


Prices displayed include 8% tax.

For Plumbing, Repair Tapes, see p. 6-2027 to 2047


TRUSCO Stock 38,650 Items

Aluminium Foil Flame Resistant Felt Tape

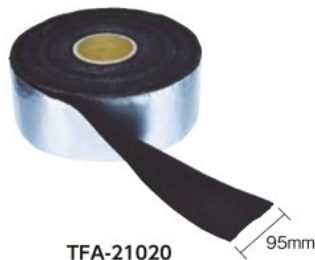

TFA-21020

- Features**
- A piping tape that sandwiches highly heat resistant glass cloth with a high heat insulation aluminium foil and a flame resistant fiber felt with excellent flame retardancy and heat insulation.
- Use**
- For heat resistance, insulation, heat retention of cables and piping.
 - As insulation material, fireproofing material and sound absorbing materials for building materials, facilities and equipment.
- Specs**
- **Not sticky (please fasten with steel wires etc.)**
 - Working temperature range: Approx. 200° C (150° C recommended)
- Materials**
- Aluminum foil
 - Glass fiber
 - Flame resistant felt
- Origin**
- Japan

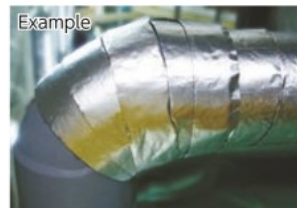

Order Unit: 1 Roll

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per roll)	MSRP (per roll)	W x L (mm x m)	Thickness (mm)	SPQ (roll)	Weight (kg)
855-1533	TFA-21020	¥32,400	¥35,000	95 x 19	2.0	4	930
855-1534	TFA-41010	¥24,069	¥26,000	95 x 9	4.0	4	700


Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Ceramic Burned Cloth (plain weave)



TSCBT2-50-30 (tape type)

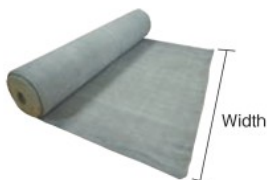

TSCBT-3-10R (roll type)

- Features**
- Asbestos is not included at all.
 - Product regulated by RCF (refractory ceramic fiber).
- Use**
- For slow cooling and annealing after welding.
- Specs**
- JIS A 1323 Class A passing product (roll type only)
 - Instantaneous heat resistant temperature: 900° C
 - Working temperature range: 800° C
 - **None adhesive (please fasten with steel wires etc.)**
- Materials**
- Ceramic Fiber: 80 to 85%
 - Organic fiber: 15 to 20%
- Origin**
- China

Tape Type

Order Unit: 1 Roll

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per roll)	MSRP (per roll)	W x L (mm x m)	Thickness (mm)	SPQ (roll)	Weight (kg)
437-4576	TSCBT2-50-30	¥19,412	¥20,970	50 x 30	2	10	1.5
437-4584	TSCBT2-100-30	¥38,805	¥41,920	100 x 30	2	5	2.9

Roll Type

Order Unit: 1 Roll

(Price revision date: Jan, 2017)

Order Code	Item No.	Price (per roll)	MSRP (per roll)	W x L (mm x m)	Thickness (mm)	SPQ (roll)	Weight (kg)
437-4592	TSCBT-2-10R	¥54,969	¥59,380	1000 x 10	2	2	10.0
437-4606	TSCBT-3-10R	¥82,389	¥89,000	1000 x 10	3	1	11.5

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Silica Cloth (twill weave)



TST-0850 (tape type)



TST-06-1000 (roll type)

- Features**
- High purity silica fiber with 95% silicone dioxide (SiO2) is used.
 - Superior in thermal impact resistance and it can withstand rapid heating and quenching.
 - Asbestos and RCF (refractory ceramic fiber) are not contained.
- Use**
- High temperature insulation material, heat insulation materials for exhaust ducts, high temperature buffer material and other high temperature areas.
- Specs**
- Working Temperature Range: Up to 1000° C
 - **None adhesive (please fasten with steel wires etc.)**
- Materials**
- Silica fiber

Tape Type

Origin • Japan

Order Unit: 1 Roll

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per roll)	MSRP (per roll)	W x L (mm x m)	Thickness (mm)	SPQ (roll)	Weight (kg)
301-7095	TST-0850	¥27,762	¥29,990	50 x 30	0.8	10	0.9
301-7109	TST-1350	¥56,820	¥61,380	50 x 30	1.3	10	1.8

Roll Type

Origin • Latvia

Order Unit: 1 Roll

(Price revision date: Jan, 2016)

Order Code	Item No.	Price (per roll)	MSRP (per roll)	W x L (mm x m)	Thickness (mm)	SPQ (roll)	Weight (kg)
473-6788	TST-06-1000	¥73,872	¥79,800	1000 x 20	0.64	1	13.7

Contact us:0120-509-849 <http://www.orange-book.com/>