

Hoses for Sprinkling

The number next to the logo mark indicates items in stock for each brand.

Hoses • Connectors

Hoses for Sprinkling
Hoses for Food

Hoses for Industry

Hoses for Drainage

Hose Couplings

Suction Hoses

Hose Bands

Hose Reels

Hose Nozzles

Equipments for Hose

Sprinklers

Snow-Melting Hoses

Automatic Sprinkling Systems

Sprinkling Tubes, Sprinkling Hoses

Outdoor Sinks

Watering Cans, Jugs

Rain Keepers

TRUSCO
Stock 38,650 Items

High Performance Hose

Emergency Stock

For Faucet Plug Sets, see p. 9-1308




GHS-50 (inner diameter 12.5mm type)



GHO-20 (inner diameter 15mm type)

- Features** • Cold/pressure hose resistant that is soft and durable and hard to fold.
Use • For watering.
Specs • Working temperature: 0 to 60°C
 • Color: Blue
Materials • PVC Resin Vinyl (PVC) + Polyester Thread
Origin • Japan

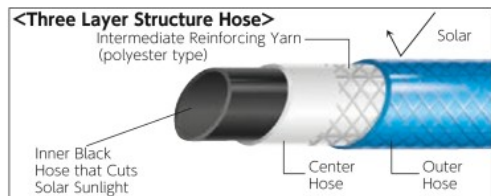

Inner diameter 12.5mm type

Order Unit: 1 Roll (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Length (m)	Inner Diameter x Outer Diameter (mm)	Working Pressure (MPa)	Min Bend Radius (mm or more)	SPQ (roll)	Weight (kg)
452-3971	GHS-20	¥ 4,870	¥ 5,260	20	12.5 x 17	0.78	63	8	2.7
452-3962	GHS-50	¥ 10,970	¥ 11,850	50	12.5 x 17	0.78	63	3	7.1

Inner Diameter 15mm Type

Order Unit: 1 Roll (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Length (m)	Inner Diameter x Outer Diameter (mm)	Working Pressure (MPa)	Min Bend Radius (mm or more)	SPQ (roll)	Weight (kg)
228-2755	GHO-5	¥ 1,481	¥ 1,600	5	15 x 20	0.6	80	20	0.9
228-2763	GHO-10	¥ 2,906	¥ 3,140	10	15 x 20	0.6	80	10	1.8
231-5904	GHO-20	¥ 5,814	¥ 6,280	20	15 x 20	0.6	80	8	3.7
765-1937	GHO-30	¥ 8,720	¥ 9,420	30	15 x 20	0.6	80	4	5.4
158-2437	GHO-50	¥ 12,914	¥ 13,950	50	15 x 20	0.6	80	3	9.5

Contact us: 0120-509-849 <http://www.orange-book.com/>

TAKAGI
Stock 268 Items

"Garden Twister"



PH02015NB030TTM

- Features** • Hose with spiral structure to prevent twist. • Dry surface reduces sticking together of hoses.
Use • For watering.
Specs • Working Temperature Range: -5 to 60°C • Anti-algae specification
 • Color: Navy
Materials • PVC Resin Vinyl (PVC) + Polyester Thread
Origin • Japan

Order Unit: 1 Roll TAKAGI Co.Ltd

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Length (m)	Inner Diameter x Outer Diameter (mm)	Working Pressure (MPa)	SPQ (roll)	Weight (kg)
453-6045	PH02015NB005TTM	¥ 1,009	-	5	15 x 20	0.7	24	0.9
453-6053	PH02015NB010TTM	¥ 2,016	-	10	15 x 20	0.7	12	1.8
453-6061	PH02015NB020TTM	¥ 4,029	-	20	15 x 20	0.7	6	3.7
453-6070	PH02015NB030TTM	¥ 6,048	-	30	15 x 20	0.7	4	5.5
453-6088	PH02015NB050TMB	¥ 10,081	-	50	15 x 20	0.7	1	9.1

Contact us: 0120-37-5580 <http://www.takagi.co.jp/>

TAKAGI
Stock 268 Items

Pressure Resistant Garden Hose



PH04015FJ050TM

- Features** • Standard pressure resistant hose.
Use • For watering.
Specs • Working Temperature Range: -5 to 60°C • Color: Blue
Materials • Hose: Vinyl chloride resin • Reinforcing layer: With polyester yarn
Origin • Japan

Order Unit: 1 Roll TAKAGI Co.Ltd

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Length (m)	Inner Diameter x Outer Diameter (mm)	Working Pressure (MPa)	SPQ (roll)	Weight (kg)
469-6514	PH04015FJ010TM	¥ 1,646	-	10	15 x 20	0.7	12	1.6
469-6522	PH04015FJ020TM	¥ 3,293	-	20	15 x 20	0.7	6	3.1
469-6531	PH04015FJ030TM	¥ 4,937	-	30	15 x 20	0.7	4	4.7
469-6549	PH04015FJ050TM	¥ 8,230	-	50	15 x 20	0.7	1	7.8

Contact us: 0120-37-5580 <http://www.takagi.co.jp/>


SANYOKASEI
Stock 54 Items

"Gusset Hose"



GA-1520D50CB

- Features** • Water flows smoothly since it is hard to be twisted.
Use • For watering.
Specs • Working temperature: 0 to 60°C
 • Food Sanitation Act compliant product
 • Color: Blue
Materials • PVC Resin Vinyl (PVC) + Polyester Thread
Origin • Japan

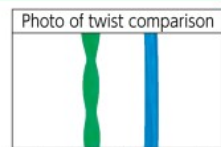

Hard to be twisted with knitting method

Order Unit: 1 Roll SANYOKASEI Co.Ltd

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Length (m)	Inner Diameter x Outer Diameter (mm)	Working Pressure (MPa)	Min Bend Radius (mm or more)	SPQ (roll)	Weight (kg)
331-3492	GA-1520D50CB	¥ 13,446	-	50	15 x 20	0.7	79	3	9.6

Contact us: 0268-62-1631 <http://www.sanyokasei.co.jp/>