

# Flip-up Top Conference Tables

For Meeting Chairs, see p. 10-76 to 86

The number next to the logo mark indicates items in stock for each brand.

Desks

PC Desks

Meeting Tables

Cafeteria Tables

Office Chairs

Meeting Chairs

Working Chairs

Anti-Static Stools

Benches

Umbrella Stands

Reception Room Furnitures

Hanger Racks

Partitions

Book Cabinets

Counters

Filing Cabinets

Catalog Cases

Map Cases/Letter Cases

Pamphlet Stands

File Wagons

Lockers

Shoes Boxes

Safes

Mailboxes

Key Boxes

Window Films

Interior Blinds

OA Floors


System Kitchens

**TRUSCO** Stock 38,650 Items

## Folding Top Type "Flight Table"



- Features**
- Being the top board foldable from the center, it can be stored saving space.
  - Pull the handle to fold the top. The fixing bracket can be operated when the top is fully folded. You can sit when folded.
- Specs**
- With Lower Shelves
  - Folding top model
  - With caster
- Materials**
- Top board: 28mm-thick decorative melamine laminate/frame core flash, Back side: Plywood/edge profile covered with the same material as the top
  - Leg: 31.8mm steel pipe (baked coating), Φ60 nylon double wheel caster (with stopper)
- Origin**
- Japan

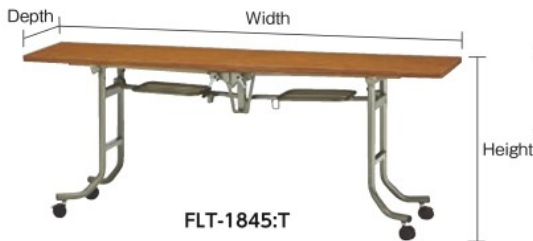

FLT-1845:T



28mm Thick Decorative Melamine Laminate Board Co-roll Top Board



(folding example)

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Options (Color)	Price (per piece)	MSRP (per piece)	Top Board Color	W x D x H (mm)	Weight (kg)
★464-5740	FLT-1845	T	¥ 59,005	¥ 63,740	Teak	1800 x 450 x 700	26.0
★464-5758	FLT-1860	T	¥ 64,939	¥ 70,150	Teak	1800 x 600 x 700	29.0
★464-5766	FLT-1875	T	¥ 97,978	¥ 105,840	Teak	1800 x 750 x 700	31.0
★464-5774	FLT-1890	T	¥ 101,013	¥ 109,120	Teak	1800 x 900 x 700	34.5

(Price revision date: Jan, 2016)

Contact us: 0120-509-849 <http://www.orange-book.com/>


**TOKIO** Stock 30 Items

## Flip-up Top Type Stack Table



- Features**
- Can be stacked by folding the top board.
  - Consists of a flip-up top with two levers mounted underneath. The top board can be folded just by operating either one of the levers.
  - Can be stored with saving space. (stacking pitch: 137mm)
- Specs**
- With Lower Shelves
- Materials**
- Top board: 28mm-thick decorative melamine laminate (frame core flash/elastomer edge)
  - Strut/leg: 25 x 50mm steel pipe (powder coating), Φ50 nylon double wheel caster with adjuster function (with stopper)
  - Shelf part: Φ 12.8mm steel pipe (powder coating)
  - Curtain Plate: Steel Sheet (powder coating)
- Origin**
- Japan

Require 2 Persons 20minutes

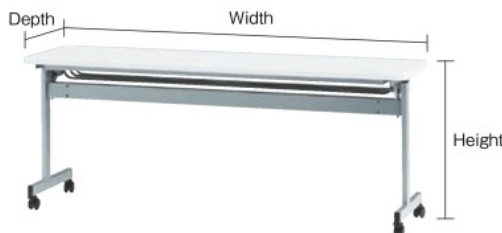

HSN-1845-W (white)

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | FUJISAWA INDUSTRY Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Top Board Color	W x D x H (mm)	Weight (kg)
★753-4400	HSN-1845-NG	¥ 38,263	¥ 49,600	New gray	1800 x 450 x 720	24.5
★753-4418	HSN-1845-RO	¥ 38,263	¥ 49,600	Rose	1800 x 450 x 720	24.5
★753-4426	HSN-1845-T	¥ 38,263	¥ 49,600	Teak	1800 x 450 x 720	24.5
★753-4434	HSN-1845-W	¥ 38,263	¥ 49,600	White	1800 x 450 x 720	24.5
★753-4442	HSN-1860-NG	¥ 44,203	¥ 57,300	New gray	1800 x 600 x 720	29.0
★753-4451	HSN-1860-RO	¥ 44,203	¥ 57,300	Rose	1800 x 600 x 720	29.0
★753-4469	HSN-1860-T	¥ 44,203	¥ 57,300	Teak	1800 x 600 x 720	29.0
★753-4477	HSN-1860-W	¥ 44,203	¥ 57,300	White	1800 x 600 x 720	29.0

(Price revision date: Jan, 2016)

Contact us: 058-247-3311 <http://www.fujisawa-co.com/>

**TOKIO** Stock 30 Items

## Flip-up Top Type Stack Table



- Features**
- Can be stacked by folding the top board.
  - Consists of a flip-up top with two levers mounted underneath. The top board can be folded just by operating either one of the levers.
  - Can be stored with saving space. (stacking pitch: 137mm)
- Specs**
- With Lower Shelves
- Materials**
- Top board: 28mm-thick decorative melamine laminate/flash structure/elastomer edge
  - Leg: 25 x 50mm steel pipe (powder coating), Φ50 nylon double wheel caster with adjuster function (with stopper)
  - Shelf part: Φ 12.8mm steel pipe (powder coating)
  - Panel: Steel plate (powder coating)
- Origin**
- Japan

Require 2 Persons 20minutes



HSN-1860P-W (white)

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | FUJISAWA INDUSTRY Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Top Board Color	W x D x H (mm)	Weight (kg)
★491-9572	HSN-1845P-NG	¥ 52,357	¥ 61,700	New gray	1800 x 450 x 720	29.7
★491-9581	HSN-1845P-RO	¥ 52,357	¥ 61,700	Rose	1800 x 450 x 720	29.7
★491-9599	HSN-1845P-T	¥ 52,357	¥ 61,700	Teak	1800 x 450 x 720	29.7
★491-9602	HSN-1845P-W	¥ 52,357	¥ 61,700	White	1800 x 450 x 720	29.7
★491-9611	HSN-1860P-NG	¥ 58,891	¥ 69,400	New gray	1800 x 600 x 720	34.2
★491-9629	HSN-1860P-RO	¥ 58,891	¥ 69,400	Rose	1800 x 600 x 720	34.2
★491-9637	HSN-1860P-T	¥ 58,891	¥ 69,400	Teak	1800 x 600 x 720	34.2
★491-9645	HSN-1860P-W	¥ 58,891	¥ 69,400	White	1800 x 600 x 720	34.2

(Price revision date: Jan, 2016)

Contact us: 058-247-3311 <http://www.fujisawa-co.com/>

