


- Desks
- PC Desks
- Meeting Tables
- Cafeteria Tables
- Office Chairs
- Meeting Chairs
- Working Chairs
- Anti-Static Stools
- Benches
- Umbrella Stands
- Reception Room Furnitures
- Hanger Racks
- Partitions
- Book Cabinets
- Counters
- Filing Cabinets
- Catalog Cases
- Map Cases/Letter Cases
- Pamphlet Stands
- File Wagons
- Lockers
- Shoes Boxes
- Safes
- Mailboxes
- Key Boxes
- Window Films
- Interior Blinds
- OA Floors
- System Kitchens

For Bases, see p. 10-152/For Shelf Boards and Fall Prevention Metal Fittings, see p. 10-164 to 165 The number next to the logo mark indicates items in stock for each brand.




A4 format standard type storage

- A4 size documents and materials can be stored efficiently.
- Tipping prevention metal fittings: Possible to compliant to TK/NTK type.

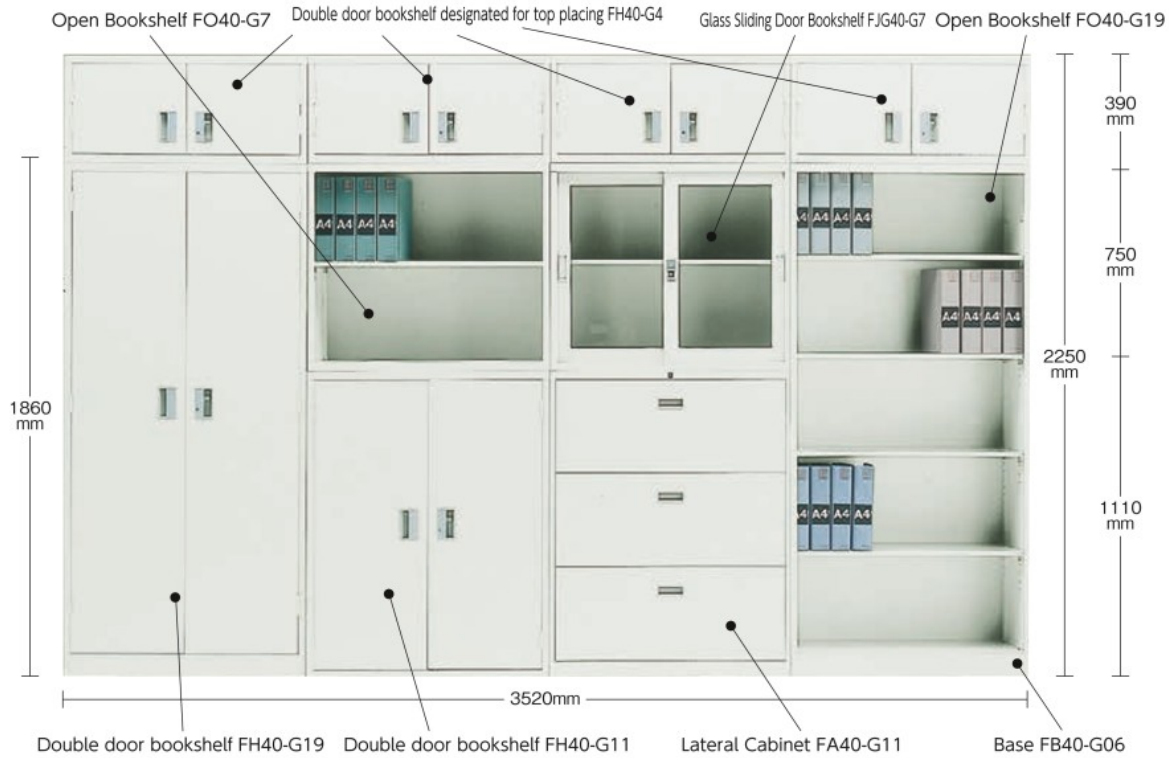


Example set reference price (tax included) **¥399,169**

Here is different! A4 format compliant and other unit storage type

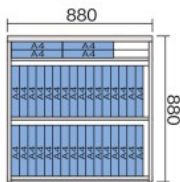

<Other Unit Bookshelves>

16 copies can be stored at each stage. Store 3 volumes in each stage. Total of 36 files can be stored in all 3 stages, but unnecessary space will be created as shown in the illustration.

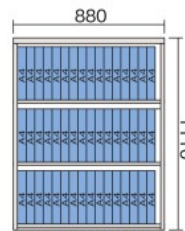

<A4 Size Correspondence> when storing an A4 size file...

It can store 16 volumes at each stage, and you can store a total of 48 files with no waste in all 3 stages.



Stock
38,650
Items

Open Bookshelf (A4 type)



- Specs
- Color: Neon Gray
 - Compatible Type Fall Prevention Metal Fittings: TK/NTK Type
- Materials
- Steel
 - Japan



NP103




FO40-G7 (files sold separately)



FO40-G11 (files sold separately)



 FO40-G19 (files sold separately)



Warning

- When using the dual purpose type for top and bottom placing as a bottom placing type, please use the base (FB40-G06).

Order Unit: 1 Piece | Factory direct | Freight: ¥2,000 | Excluding remote islands

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	Equal Load Capacity (kg/stage)	W x D x H (mm)	Installation Type	Accessories	Shelf Board Pitch (mm)	Additional Shelf Board	Weight (kg)
★509-3805	NP103	¥13,053	¥14,100	60	-	880 x 400 x 390	Designated for top placing	-	-	-	8
★520-6642	FO40-G7	¥26,383	¥28,500	120	60	880 x 400 x 750	For both top/bottom placing	Shelf board x 1	30	N-33	16
★520-6707	FO40-G11	¥31,382	¥33,900	180	60	880 x 400 x 1110	For both top/bottom placing	Shelf board x 2	30	N-33	22
★520-6791	FO40-G19	¥47,026	¥50,800	200	60	880 x 400 x 1860	Designated for bottom placing	Shelf board x 4	30	N-33	34

Contact us: 0120-509-849 <http://www.orange-book.com/>