

Prices displayed include 8% tax.



TRUSCO
Stock
38,650
 Items

Fall Prevention Metal Fitting (holding plate/floor fixing plate/connection plate)


Com
 Green Purchasing
 Chemical Content
 Inspection

Com
 Drawing


Origin • Japan

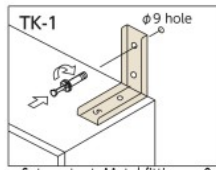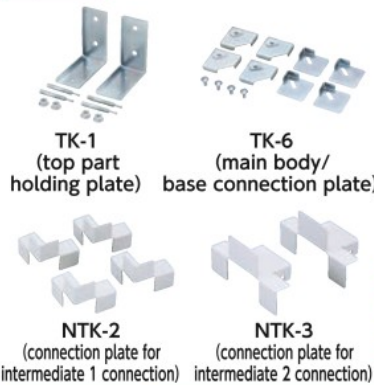


•Set content: Metal fittings x 2, screw anchor x 4

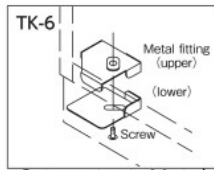

•Set content: Metal fittings x 4, bolt x 4

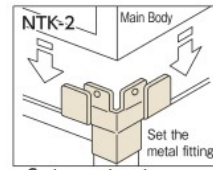

•Set content: Metal fittings x 4

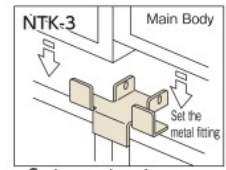

•Set content: Metal fittings x 2

Order Unit: 1 Set | Factory direct | Freight: ¥1,500 | Excluding remote islands

Order Code	Item No.	Price (per set)	MSRP (per set)	Item Name	Weight (g/set)
★518-0074	TK-1	¥2,962	¥3,200	Top part holding plate	400
★518-0104	TK-6	¥2,222	¥2,400	Main body/base connection plate	300
★520-6456	NTK-2	¥5,184	¥5,600	Connection plate for intermediate 1 connection	200
★258-5421	NTK-3	¥3,703	¥4,000	Connection plate for intermediate 2 connection	300

Contact us: 0120-509-849 <http://www.orange-book.com/>



Bookshelf

NEW Finished Goods **Heavy Caution**

Specs • Color: Warm White
 Origin • Japan

Warning

•When using as a bottom placing type, please use the following base (H337B-AW·H637B-AW).



HG337-AW

HG637-AW

HS337-AW


HS637-AW

K367-AW

Order Unit: 1 Piece | Factory direct | Shipping not included

NAIKI Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	Equal Load Capacity (kg/stage)	W x D x H (mm)	Installation Type	Accessories	Shelf Board Pitch (mm)	Additional Shelf Board	Weight (kg)
★836-9178	HG337-AW	¥47,119	¥50,900	80	40	880 x 515 x 880	For both top/bottom placing	Cylinder lock, 1 shelf board, 2 book supporters	28	SS-D435-AW	33.0
★836-9179	HG637-AW	¥79,889	¥86,300	160	40	1760 x 515 x 880	For both top/bottom placing	Cylinder lock, 2 shelf boards, 4 book supporters	28	SS-D435-AW	58.5
★836-9180	HS337-AW	¥42,120	¥45,500	80	40	880 x 515 x 880	For both top/bottom placing	Cylinder lock, 1 shelf board, 2 book supporters	28	SS-D435-AW	31.0
★836-9181	HS637-AW	¥71,558	¥77,300	160	40	1760 x 515 x 880	For both top/bottom placing	Cylinder lock, 2 shelf boards, 4 book supporters	28	SS-D435-AW	56.5
★836-9182	K367-AW	¥68,688	¥74,200	160	40	880 x 515 x 1790	Designated for bottom placing	3 shelf boards, 4 book supporters, key	30	SS-D435-AW	53.0

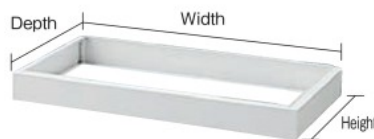

H637B-AW

Bookshelf Base

Order Unit: 1 Piece | Factory direct | Shipping not included

Order Code	Item No.	Price (per piece)	MSRP (per piece)	W x D x H (mm)	Applicable Bookshelf Dimension (mm) W x D	SPQ (piece)	Weight (kg)
★836-9183	H337B-AW	¥4,721	¥5,100	880 x 489 x 90	880 x 400	1	3.0
★836-9184	H637B-AW	¥6,943	¥7,500	1760 x 489 x 90	1760 x 400	1	4.8

Contact us: 0120-711-021 <http://www.naiki.co.jp/>

Introducing R&D Center

Introduction of Research & Development Center and Showroom of manufacturers listed in the Orange Book.

NAIKI Showroom

Opening hours 8:50 a.m. to 5:40 p.m.

Closed Sat, Sun and public holidays

NAIKI Co.Ltd. (Tokyo Branch)

JPR Nihonbashi-horidome Building, 1-11-12
 Nihonbashihoridomecho, Chuo-ku, Tokyo, 103-0012, Japan
 Tel: 03(5847)1980 Fax: 03(5847)1217



- Desks
- PC Desks
- Meeting Tables
- Cafeteria Tables
- Office Chairs
- Meeting Chairs
- Working Chairs
- Anti-Static Stools
- Benches
- Umbrella Stands
- Reception Room Furnitures
- Hanger Racks
- Partitions
- Book Cabinets
- Counters
- Filing Cabinets
- Catalog Cases
- Map Cases·Letter Cases
- Pamphlet Stands
- File Wagons
- Lockers
- Shoes Boxes
- Safes
- Mailboxes
- Key Boxes
- Window Films
- Interior Blinds
- OA Floors
- System Kitchens