


Prices displayed include 8% tax.



Stock 38,650 Items

Folder Rack

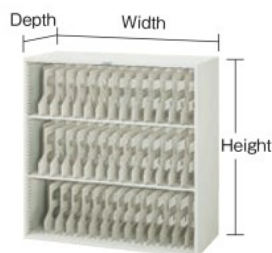

FR-303:NG



FR-603:NG

- Features**
- Since the back panels and partition panels can be moved back and forth, A4 and B4 files can be neatly stored.
 - With the partition panels that can be moved at 30mm pitch, partition can be changed according to the volume of documents.
 - A4 and B4 sized documents can be stored.
- Specs**
- Color: Neo Gray
- Materials**
- Steel
- Origin**
- Japan



TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece | Factory direct | Freight: ¥3,000 | Excluding remote islands

Order Code	Item No.	Options (Color)	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	Equal Load Capacity (kg/stage)	W x D x H (mm)	Accessories	Weight (kg)
★509-3732	FR-303	NG	¥65,170	¥70,400	180	60	880 x 400 x 880	2 shelf boards, 3 back panels, 39 partition panels	40.0
★510-1930	FR-603	NG	¥91,738	¥99,100	200	60	880 x 400 x 1760	4 shelf boards, 5 back panels, 65 partition panels	87.4



FR-1S:NG (partition panel)



FR-1BP:NG (back panel)



FR-1T:NG (shelf board)

Partition Panel

- Features**
- Partition panel with less rattling.

Order Unit: 1 Set | Factory direct | Freight: ¥1,500 | Excluding remote islands

Order Code	Item No.	Options (Color)	Price (per set)	MSRP (per set)	D x H x Thickness (mm)	Q'ty Per Set (sheet)	Weight (kg/set)
★510-6401	FR-1S	NG	¥7,591	¥8,200	325 x 220 x 1	13	3.9

Back Panel

- Features**
- The back panel firmly guards files.

Order Unit: 1 Sheet | Factory direct | Freight: ¥1,500 | Excluding remote islands

Order Code	Item No.	Options (Color)	Price (per sheet)	MSRP (per sheet)	W x D x H (mm)	Weight (kg)
★510-6397	FR-1BP	NG	¥2,870	¥3,100	840 x 150 x 220	2

Shelf Board

- Features**
- Grooves for mounting partition panels are cut at a 30mm pitch.

- Specs**
- Equal Load Capacity: 60kg/stage

Order Unit: 1 Sheet | Factory direct | Freight: ¥1,500 | Excluding remote islands

Order Code	Item No.	Options (Color)	Price (per sheet)	MSRP (per sheet)	W x D x H (mm)	Weight (kg)
★510-6389	FR-1T	NG	¥3,425	¥3,700	859 x 372 x 10	3

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 2 Items

"Easy Cabinet"



EC-001 (popular type)



ECK-001 (reinforced type/file sold separately)

- Features**
- Since metal fittings are removable type, easy to assemble and disassemble.
 - Easy separation and disposal, environmentally friendly eco series.
- Origin**
- Japan

Popular Type A4

- Features**
- Standard type that emphasizes economic efficiency and storage capacity.
 - Possible to stack up to 5 stages.

Order Unit: 1 Piece

General co.ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	W x D x H (mm)	Drawers Effective Internal Dimension (mm) W x D x H	Max Stacking	SPQ (piece)	Weight (kg)
402-8457	EC-001	¥3,024	¥3,200	370 x 600 x 288	314 x 560 x 259	5 Stages	10	2.37

Enhanced Type A4

- Features**
- Add metal fittings to the back side as well and further increase the strength, it is possible to stack up to 7 stages.

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	W x D x H (mm)	Drawers Effective Internal Dimension (mm) W x D x H	Max Stacking	SPQ (piece)	Weight (kg)
402-8465	ECK-001	¥3,024	¥3,200	370 x 600 x 288	314 x 560 x 259	7 Stages	10	2.4

Contact us: 06-6930-5301 <http://www.general.co.jp/>

Desks

PC Desks

Meeting Tables

Cafeteria Tables

Office Chairs

Meeting Chairs

Working Chairs

Anti-Static Stools

Benches

Umbrella Stands

Reception Room Furnitures

Hanger Racks

Partitions

Book Cabinets

Counters

Filing Cabinets

Catalog Cases

Map Cases·Letter Cases

Pamphlet Stands

File Wagons

Lockers

Shoes Boxes

Safes

Mailboxes

Key Boxes

Window Films

Interior Blinds

OA Floors

System Kitchens