

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

## Map Case "A3 Type"



- Features** • Steel drawers are resistant to impact and very strong.
- Specs** • A3 drawer: A3-1 \*There is no partition panel setting
- Materials** • All Steel Type
- Accessories** • Steel
- With a header card and a cell cover for each drawer stage.
- Origin** • Japan

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	W x D x H (mm)	Drawers Effective Internal Dimension (mm) W x D x H	Number of Steps	Type	SPQ (piece)	Weight (kg)
★504-7595	A3-1W5	¥34,251	¥37,000	20	541 x 360 x 329	478 x 337 x 47	5 Stages	For A3	1	13.0
★504-7609	A3-1W9	¥55,728	¥60,200	35	541 x 360 x 541	478 x 337 x 47	9 Stages	For A3	1	20.8
★504-7633	A3-1W12	¥68,688	¥74,200	50	541 x 360 x 700	478 x 337 x 47	12 Stages	For A3	1	26.7
★504-7650	A3-1W15	¥82,111	¥88,700	60	541 x 360 x 880	478 x 337 x 47	15 Stages	For A3	1	32.8

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

## Map Case "A2 Type"



- Features** • Steel drawers are resistant to impact and very strong.
- Specs** • A2 drawer: A2-1 \*There is no partition panel setting
- Materials** • All Steel Type
- Accessories** • Steel
- With a header card and a cell cover for each drawer stage.
- Origin** • Japan

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands


TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	W x D x H (mm)	Drawers Effective Internal Dimension (mm) W x D x H	Number of Steps	Type	SPQ (piece)	Weight (kg)
★504-7617	A2-1W5	¥43,416	¥46,900	30	696 x 480 x 329	633 x 457 x 47	5 Stages	For A2	1	20.7
★504-7625	A2-1W9	¥67,207	¥72,600	50	696 x 480 x 541	633 x 457 x 47	9 Stages	For A2	1	33.3
★504-7641	A2-1W12	¥84,055	¥90,800	65	696 x 480 x 700	633 x 457 x 47	12 Stages	For A2	1	42.9
★504-7668	A2-1W15	¥98,681	¥106,600	80	696 x 480 x 880	633 x 457 x 47	15 Stages	For A2	1	52.6

Contact us:0120-509-849 <http://www.orange-book.com/>

DAISHIN

## Map Case "A1, A2 Type"

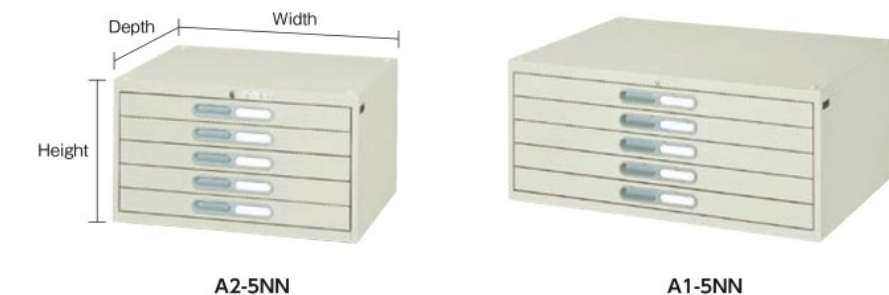

- Features** • Can be store drawings and paper without folding.
- Specs** • With Key Type
- Materials** • All Steel Type
- Origin** • Steel
- Japan

**Warning**  
• Partition panel is optional.

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands

DAISHIN KOGYO Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	W x D x H (mm)	Drawers Effective Internal Dimension (mm) W x D x H	Number of Steps	Type	SPQ (piece)	Weight (kg)
★799-4711	A2-5NN	¥74,512	¥74,300	50	730 x 565 x 415	641 x 467 x 45	5 Stages	For A2	1	39.8
★799-4702	A1-5NN	¥95,472	¥95,200	75	978 x 740 x 415	889 x 642 x 45	5 Stages	For A1	1	62.8

Contact us:06-6901-5551 <http://www.daishinkogyo.co.jp/>

- Desks
- PC Desks
- Meeting Tables
- Cafeteria Tables
- Office Chairs
- Meeting Chairs
- Working Chairs
- Anti-Static Stools
- Benches
- Umbrella Stands
- Reception Room Furnitures
- Hanger Racks
- Partitions
- Book Cabinets
- Counters
- Filing Cabinets
- Catalog Cases
- Map Cases·Letter Cases
- Pamphlet Stands
- File Wagons
- Lockers
- Shoes Boxes
- Safes
- Mailboxes
- Key Boxes
- Window Films
- Interior Blinds
- OA Floors
- System Kitchens