

TRUSCO



Stock 38,650 Items

Holder Type Clip "Clicks"

Com Drawing



TC-C6C5-1



TC-C5C5-3



TC-C1C5-5



TC-LC1LC3-1



TC-LC1LC3-50



TC-GC1GC1-1



TC-GC1GC1-3



TC-GC1GC1-3



TC-GC1GC3-1



TC-GC1GC3-3



TC-STB-WB



TC-C6BASE-50



TC-C6BASE-100



TC-C66

Features

- According to the object to be pinched, there are clip type, base type for fratty placing, magnet type.
- Small clip or more clip uses a stainless steel mechanical spring and has a strong grip force.
- The joint part can be adjusted 360° angle freely.

Origin


- Japan

Item No. Example

TC - C5C5 - 3



Indicates the type of the joint
 1=Joint 1 Series 3=Joint 3 Series
 5=Joint 5 Series
 50=Straight Bar 50mm
 100=Straight Bar 100mm

Indicate the type of clip/base/magnet
 WS=Ultra Small Clip C1=Small Clip C5=Medium Clip
 C6=Wide Clip LC1=Large Clip LC3= Large Wide Clip
 GC1=Ultra Large Clip GC3=Ultra Large Wide Clip
 MGB= Neoji Magnet MG=Normal Magnet
 KMG=Powerful Magnet LCMG=Super Strong Magnet
 STB=30mm Square Pedestal BASE=Φ100mm Pedestal

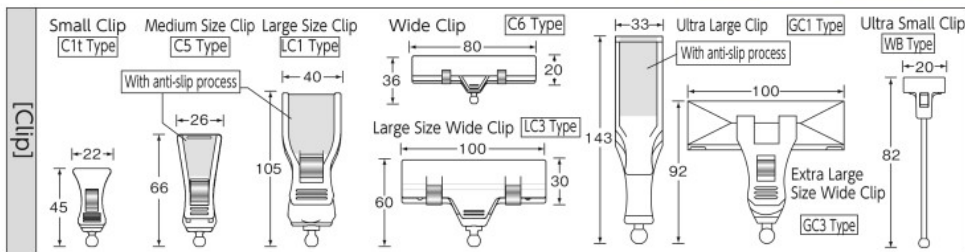

Max Opening Amount

C1 Type	10mm
C5 Type	31mm
LC1 Type	50mm
C6 Type	10mm
LC3 Type	11mm
GC1 Type	55mm
GC3 Type	22mm
WB Type	2.5mm

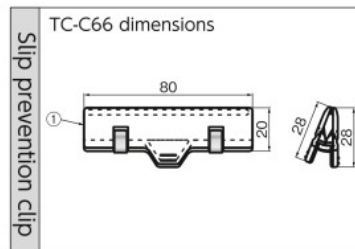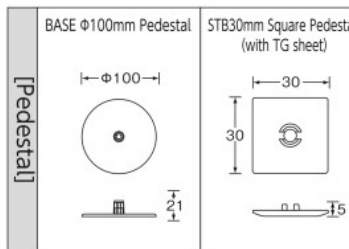

None Magnets

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Clip Type + Joint Type + Clip Type	Type	Total Length (mm)	SPQ (piece)	Weight (g)
447-3329	TC-C6C5-1	¥ 342	¥ 370	C6 Type + Joint 1 Series + C5 Type	Simple	95	10	24
261-9563	TC-C6C5-3	¥ 370	¥ 400	C6 Type + Joint 3 Series + C5 Type	Multi Movable	135	10	26
261-9571	TC-C5C5-3	¥ 379	¥ 410	C5 Type + Joint 3 Series+ C5 Type	Multi Movable	165	10	27
261-9580	TC-C1C5-3	¥ 334	¥ 360	C1 Type + Joint 3 Series + C5 Type	Multi Movable	145	10	19
261-9598	TC-C6C5-5	¥ 444	¥ 480	C6 Type + Joint 5 Series + C5 Type	Multi Movable	165	10	28
261-9601	TC-C5C5-5	¥ 454	¥ 490	C5 Type + Joint 5 Series+ C5 Type	Multi Movable	200	10	30
261-9610	TC-C1C5-5	¥ 407	¥ 440	C1 Type + Joint 5 Series + C5 Type	Multi Movable	175	10	22
261-9628	TC-C6C5-50	¥ 361	¥ 390	C6 Type + Straight 50 + C5 Type	Straight bar	160	10	26
261-9636	TC-C5C5-50	¥ 370	¥ 400	C5 Type + Straight 50 + C5 Type	Straight bar	190	10	28
261-9644	TC-C1C5-50	¥ 324	¥ 350	C1 Type + Straight 50 + C5 Type	Straight bar	170	10	19
261-9652	TC-C6C5-100	¥ 379	¥ 410	C6 Type + Straight 100 + C5 Type	Straight bar	210	10	29
261-9661	TC-C5C5-100	¥ 389	¥ 420	C5 Type + Straight 100 + C5 Type	Straight bar	240	10	31
261-9679	TC-C1C5-100	¥ 342	¥ 370	C1 Type + Straight 100 + C5 Type	Straight bar	220	10	22
855-3346	TC-C6LC1-50	¥ 630	¥ 680	C6 Type + Straight 50 + LC1 Type	Straight bar	200	10	60
855-3347	TC-C6LC1-100	¥ 648	¥ 700	C6 Type + Straight 100 + LC1 Type	Straight bar	250	10	63
447-3370	TC-LC1LC3-1	¥ 741	¥ 800	LC1 Type + Joint 1 Series + LC3 Type	Large	165	10	75
447-3388	TC-LC1LC3-50	¥ 889	¥ 960	LC1 Type + Straight Bar 50 + LC3 Type	Large	220	10	78
769-0771	TC-GC1GC1-1	¥1,389	¥1,500	GC1 Type + Joint 1 Series+ GC1 Type	Super large type	290	5	115
769-0789	TC-GC1GC1-3	¥1,666	¥1,800	GC1 Type + Joint 3 Series+ GC1 Type	Super large type	340	5	128
769-0797	TC-GC1GC3-1	¥1,111	¥1,200	GC1 Type + Joint 1 Series+ GC3 Type	Super large type	205	5	92
769-0801	TC-GC1GC3-3	¥1,389	¥1,500	GC1 Type + Joint 3 Series+ GC3 Type	Super large type	255	5	105
769-0908	TC-STB-WB	¥ 741	¥ 800	WB Type + STB Type	Base	84	5	4
447-3311	TC-C6BASE-50	¥ 444	¥ 480	C6 Type + Straight bar 50 + Base 100Φ	Base	100	10	39
447-3302	TC-C6BASE-100	¥ 463	¥ 500	C6 Type + Straight bar 100 + Base 100Φ	Base	150	10	41

Slip Prevention Clip

Features

- With its slip prevention effect, it has approx. 2.5-fold of grip force compared with a type without slip prevention, so it securely holds exhibit items.

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Clip type	Type	Qty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
855-2620	TC-C66	¥685	¥740	C66 type	Slip prevention clip	4	10	10

Contact us:0120-509-849 <http://www.orange-book.com/>