
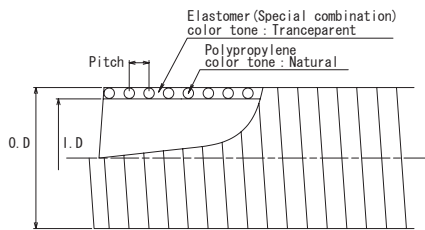


# TOTAKU ECO SD-C

Item No.22182-

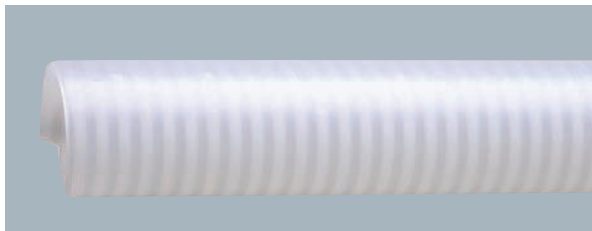

## STANDARD DIMENSIONS & PROPERTIES

Nominal diameter	I.D.	O.D.	Weight (reference)	L/coil	Allowable pressure (at room temperature)		Allowable bending radius	
					MPa	kgf/cm <sup>2</sup>		
38	1 1/4	38.0	46.6	485	50	0.30	2.9	240
50	2	50.8	60.6	805	50	0.20	2.0	360

## Features.

- For transportation of foodstuffs
- ※ No- suitable for transportation of oily foodstuffs or fluid
- Conformed to “Food Sanitary Law, Notification of Ministry of Health, Labour and Welfare No.201” (Except for dissolving test on oils and fats and fat-related food, Heptanes).
- Excellent in heat-resistance and flexibility
- Can be washed by hot water\*1 or 95% ethanol, and keep cleanliness
- Excellent in lightness, flexibility, and abrasion-resistance
- Smooth inner and outer surface.
- Translucent wall enables visual check of the material flow.
- ※ 1. Conditions of Hot Water Washing: Temperature: 80°C or less, Pressure: 0.1MPa or less, Pressurization time: up to 3 minutes.

## Applications.



- For transportation of sake, liquor, soft-drinks, etc
- Additionally, for transportation of other foodstuffs
- For suction and delivery of general usage
- ※ Please take a range of 0°C to 50°C as standard allowable temperature, subject to change of allowable pressure depending on use temperature. In case of continuous use, 40°C or less is recommended.

## CAUTIONS

Please avoid the use and storage over the long period of time in the outdoors.

# TOTAKU ECO SD-AS

Item No.22183-

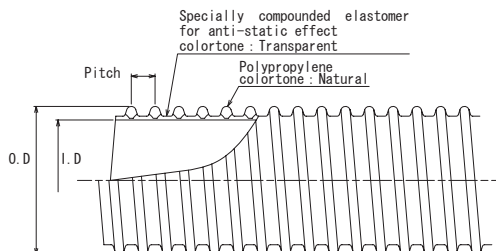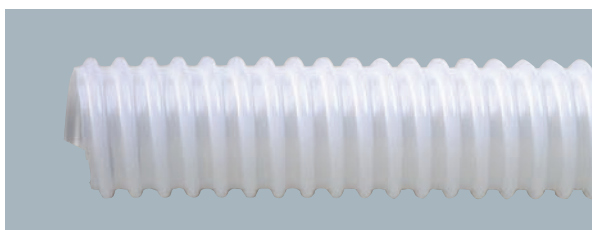

## STANDARD DIMENSIONS & PROPERTIES

Nominal diameter	I.D.	O.D.	Pitch	Weight (reference)	L/coil	Allowable pressure (at room temperature)		Allowable bending radius	
						MPa	kgf/cm <sup>2</sup>		
38	1 1/4	38.0	48.0	9.0	340	50	0.10	1.0	150
50	2	50.8	62.0	10.0	550	50	0.10	1.0	195
65	2 1/2	63.5	76.0	14.3	695	20	0.10	1.0	255
75	3	76.2	92.5	15.8	950	20	0.10	1.0	255
100	4	101.6	120.0	18.0	1600	20	0.10	1.0	450

## Features.

- For transporting of foodstuffs
- ※ No suitable for transportation of oily foodstuffs or fluid
- Conformed to “Food Sanitary Law, Notification of Ministry of Health, Labour and Welfare No.201” (Except for dissolving test on oils and fats and fat-related food, Heptanes).
- Less inner resistance enables more transportability.
- High anti-static performance.
- Lightweight, very flexible and superior abrasion resistance.
- Translucent wall enables visual check of the material flow.

## Applications.

- For transportation of plastic pellets (For food packaging's and toys, etc.)
- For transportation of powder & granule of foodstuffs
- For transportation of medicines
- Additionally, for transportation of powder & granule form besides the food
- ※ Please take a range of 0°C to 50°C as standard allowable temperature, subject to change of allowable pressure depending on use temperature. In case of continuous use, 40°C or less is recommended.

## CAUTIONS

Please avoid the use and storage over the long period of time in the outdoors.