




# ドリルスリーブ・BSスリーブ・特殊スリーブ

焼入研磨品

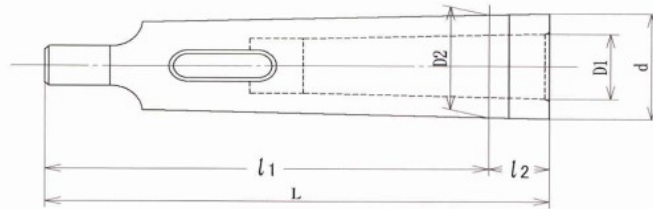

呼び	内側テーパ×外側テーパ	D1	D2	d	L	l <sub>1</sub>	l <sub>2</sub>
ドリルスリーブ	1 × 2	12.065	17.780	18.0	92	75	17
	1 × 3		23.825	24.1	100	94	6
	1 × 4		31.267	31.6	124	117.5	6.5
	1 × 5		44.399	44.7	156	149.5	6.5
	1 × 6	63.348	63.8	220	210	10	
	2 × 3	17.780	23.825	24.1	112	94	18
	2 × 4		31.267	31.6	124	117.5	6.5
	2 × 5		44.399	44.7	156	149.5	6.5
	2 × 6		63.348	63.8	220	210	10
	3 × 4	23.825	31.267	31.6	136	117.5	18.5
	3 × 5		44.399	44.7	156	149.5	6.5
	3 × 6		63.348	63.8	220	210	10
	4 × 5	31.267	44.399	44.7	168	149.5	18.5
	4 × 6		63.348	63.8	220	210	10
	4 × 7		83.058	83.6	296	286	10
	5 × 6	44.399	63.348	63.8	225	210	15
5 × 7	83.058		83.6	296	286	10	
6 × 7	63.348	83.058	83.6	296	286	10	

呼び	内側テーパ×外側テーパ	内側テーパ	外側テーパ	L
BSスリーブ	※ BS5 × BS 7	BS5	BS 7	100
	※ BS5 × BS 9		BS 9	132
	※ BS5 × BS10		BS10	160
	※ BS7 × BS 9	BS7	BS 9	132
	※ BS7 × BS10		BS10	160
	※ BS9 × BS10	BS9	BS11	185
	※ BS9 × BS11		BS12	
	※ BS9 × BS12			

呼び	内側テーパ×外側テーパ	内側テーパ	外側テーパ	L
特殊スリーブ	※ MT1 × BS 7	MT 1	BS 7	100
	※ MT1 × BS 9		BS 9	122
	※ MT2 × BS 9	MT 2	BS10	127
	※ MT2 × BS10		BS10	149
	※ BS5 × MT 2	BS 5	MT 2	85
	※ BS5 × MT 3		MT 3	100
	※ BS5 × MT 4		MT 4	137
	※ BS7 × MT 3	BS 7	MT 3	120
	※ BS7 × MT 4		MT 4	135
	※ BS7 × MT 5		MT 5	157
	※ BS9 × MT 4	BS 9	MT 4	160
	※ BS9 × MT 5		MT 5	168
	※ BS9 × MT 6		MT 6	220
	※ BS10 × MT 5	BS10	MT 5	160
※ BS10 × MT 6	MT 6			