
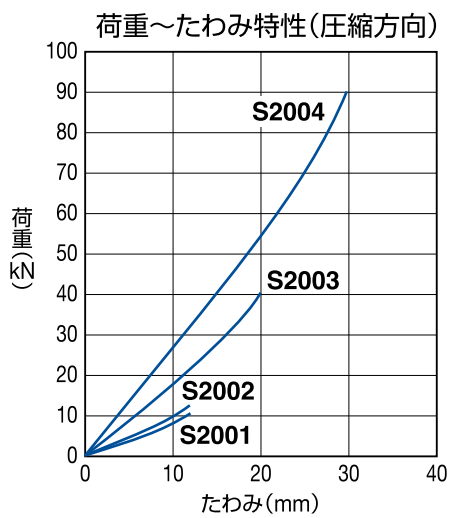


ストッパー S2000型

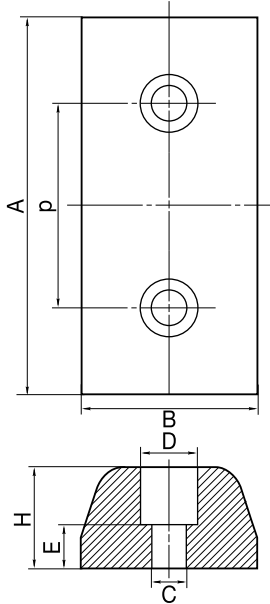

特性値	反力 (N)	ストローク (mm)	吸収エネルギー (J)	重量 (g)
S2001	10500	12	64.5	390
S2002	13500	12	82.5	580
S2003	40000	20	400	1850
S2004	90000	30	1350	6100

製品寸法	A	B	C	D	E	H	p
S2001	120	80	17	30	20	47	60
S2002	180	80	23	35	20	47	100
S2003	252	112	24	42	24	66	140
S2004	382	170	36	64	36	100	210