
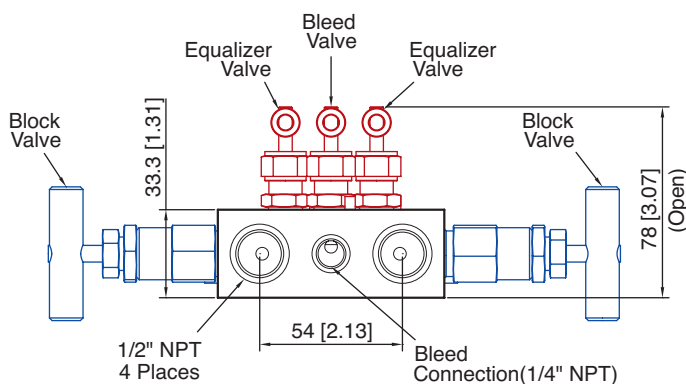
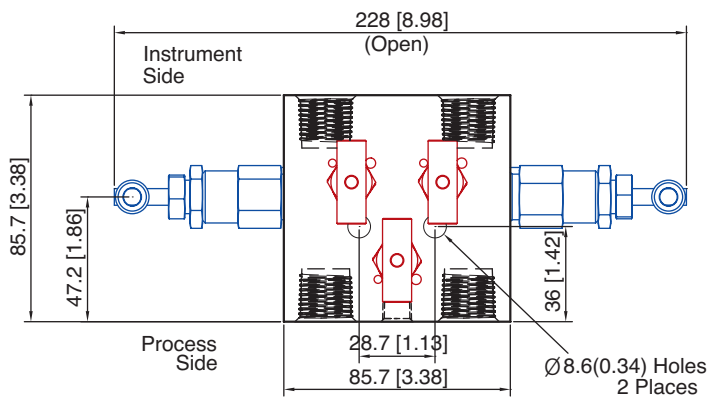
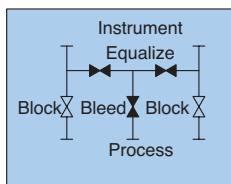


VMR series

(5Way, Remote Mounting Type)

VMR5A-08N-

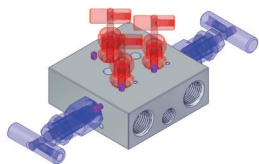

Pressure - Temperature Ratings by Packing Materials

Packing Material	Body Material	Temperature Rating		Pressure Rating at 37° C (100° F)		Pressure Rating at Maximum Temperature			
		° C	° F	psig	bar	psig	bar	° C	° F
PTFE	316SS	-54~232	-65~450	6000	413	4130	285	232	450
	Alloy 400	-54~232	-65~450	5000	345	3970	274	232	450
Grafoil	316SS	-54~648	-65~1200	6000	413	1715	118	648	1200
	Alloy 400	-54~260	-65~500	5000	345	3970	274	260	500

Alloy 400/Monel is not applicable over 260° C (500° F).

Dimensions are for reference only and are subject to change without prior notice.