


3GT

〈ピッチ:3.0mm〉

● ベルト歯形寸法

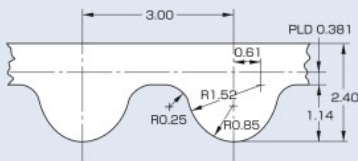


● ベルト呼称例

300-3GT-6




● プーリ歯形寸法

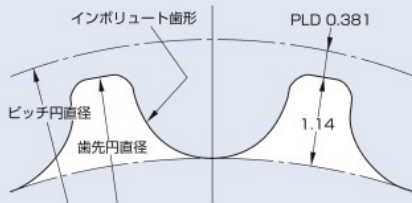

● プーリ呼称例

P 30-3GT-6-6F

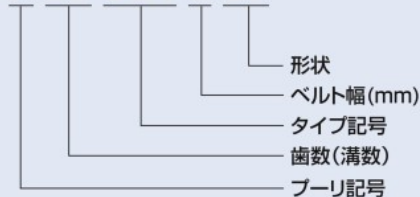

3GTプーリ

P.118

参照

ベルトサイズ一覧表

呼称	ピッチ周長(mm)	歯数
81-3GT	81.00	27
93-3GT	93.00	31
102-3GT	102.00	34
105-3GT	105.00	35
108-3GT	108.00	36
111-3GT	111.00	37
114-3GT	114.00	38
117-3GT	117.00	39
120-3GT	120.00	40
123-3GT	123.00	41
126-3GT	126.00	42
129-3GT	129.00	43
132-3GT	132.00	44
135-3GT	135.00	45
138-3GT	138.00	46
141-3GT	141.00	47
144-3GT	144.00	48
147-3GT	147.00	49
150-3GT	150.00	50
156-3GT	156.00	52
159-3GT	159.00	53
162-3GT	162.00	54
168-3GT	168.00	56
174-3GT	174.00	58
177-3GT	177.00	59
180-3GT	180.00	60
186-3GT	186.00	62
189-3GT	189.00	63
192-3GT	192.00	64
195-3GT	195.00	65
198-3GT	198.00	66
201-3GT	201.00	67
204-3GT	204.00	68
207-3GT	207.00	69
210-3GT	210.00	70
213-3GT	213.00	71
216-3GT	216.00	72
219-3GT	219.00	73
222-3GT	222.00	74
225-3GT	225.00	75
228-3GT	228.00	76
231-3GT	231.00	77
234-3GT	234.00	78
237-3GT	237.00	79
240-3GT	240.00	80
243-3GT	243.00	81
246-3GT	246.00	82
249-3GT	249.00	83
252-3GT	252.00	84
255-3GT	255.00	85
258-3GT	258.00	86
264-3GT	264.00	88
267-3GT	267.00	89
270-3GT	270.00	90
273-3GT	273.00	91
276-3GT	276.00	92
282-3GT	282.00	94
285-3GT	285.00	95
288-3GT	288.00	96
291-3GT	291.00	97
294-3GT	294.00	98
297-3GT	297.00	99
300-3GT	300.00	100
303-3GT	303.00	101
309-3GT	309.00	103
312-3GT	312.00	104
315-3GT	315.00	105
318-3GT	318.00	106
324-3GT	324.00	108
327-3GT	327.00	109
330-3GT	330.00	110
333-3GT	333.00	111
336-3GT	336.00	112
339-3GT	339.00	113
342-3GT	342.00	114
345-3GT	345.00	115
348-3GT	348.00	116
351-3GT	351.00	117
354-3GT	354.00	118
357-3GT	357.00	119

呼称	ピッチ周長(mm)	歯数
363-3GT	363.00	121
366-3GT	366.00	122
369-3GT	369.00	123
375-3GT	375.00	125
378-3GT	378.00	126
381-3GT	381.00	127
384-3GT	384.00	128
387-3GT	387.00	129
393-3GT	393.00	131
396-3GT	396.00	132
399-3GT	399.00	133
402-3GT	402.00	134
405-3GT	405.00	135
408-3GT	408.00	136
414-3GT	414.00	138
417-3GT	417.00	139
420-3GT	420.00	140
423-3GT	423.00	141
426-3GT	426.00	142
432-3GT	432.00	144
444-3GT	444.00	148
447-3GT	447.00	149
453-3GT	453.00	151
456-3GT	456.00	152
459-3GT	459.00	153
462-3GT	462.00	154
468-3GT	468.00	156
471-3GT	471.00	157
480-3GT	480.00	160
486-3GT	486.00	162
489-3GT	489.00	163
495-3GT	495.00	165
501-3GT	501.00	167
504-3GT	504.00	168
510-3GT	510.00	170
513-3GT	513.00	171
519-3GT	519.00	173
522-3GT	522.00	174
525-3GT	525.00	175
531-3GT	531.00	177
537-3GT	537.00	179
540-3GT	540.00	180
543-3GT	543.00	181
549-3GT	549.00	183
552-3GT	552.00	184
558-3GT	558.00	186
561-3GT	561.00	187
564-3GT	564.00	188
570-3GT	570.00	190
576-3GT	576.00	192
579-3GT	579.00	193
582-3GT	582.00	194
588-3GT	588.00	196
591-3GT	591.00	197
594-3GT	594.00	198
597-3GT	597.00	199
600-3GT	600.00	200
603-3GT	603.00	201
609-3GT	609.00	203
612-3GT	612.00	204
618-3GT	618.00	206
624-3GT	624.00	208
633-3GT	633.00	211
639-3GT	639.00	213
642-3GT	642.00	214
645-3GT	645.00	215
648-3GT	648.00	216
651-3GT	651.00	217
654-3GT	654.00	218
660-3GT	660.00	220
666-3GT	666.00	222
672-3GT	672.00	224
675-3GT	675.00	225
681-3GT	681.00	227
687-3GT	687.00	229
690-3GT	690.00	230
693-3GT	693.00	231
699-3GT	699.00	233
702-3GT	702.00	234
705-3GT	705.00	235

呼称	ピッチ周長(mm)	歯数
708-3GT	708.00	236
720-3GT	720.00	240
723-3GT	723.00	241
729-3GT	729.00	243
741-3GT	741.00	247
744-3GT	744.00	248
750-3GT	750.00	250
756-3GT	756.00	252
765-3GT	765.00	255
774-3GT	774.00	258
783-3GT	783.00	261
789-3GT	789.00	263
810-3GT	810.00	270
822-3GT	822.00	274
840-3GT	840.00	280
852-3GT	852.00	284
858-3GT	858.00	286
870-3GT	870.00	290
882-3GT	882.00	294
900-3GT	900.00	300
912-3GT	912.00	304
924-3GT	924.00	308
927-3GT	927.00	309
936-3GT	936.00	312
948-3GT	948.00	316
960-3GT	960.00	320
963-3GT	963.00	321
966-3GT	966.00	322
972-3GT	972.00	324
981-3GT	981.00	327
993-3GT	993.00	331
996-3GT	996.00	332
1005-3GT	1005.00	335
1008-3GT	1008.00	336
1014-3GT	1014.00	338
1050-3GT	1050.00	350
1059-3GT	1059.00	353
1068-3GT	1068.00	356
1071-3GT	1071.00	357
1086-3GT	1086.00	362
1098-3GT	1098.00	366
1113-3GT	1113.00	371
1137-3GT	1137.00	379
1170-3GT	1170.00	390
1188-3GT	1188.00	396
1212-3GT	1212.00	404
1215-3GT	1215.00	405
1260-3GT	1260.00	420
1290-3GT	1290.00	430
1299-3GT	1299.00	433
1305-3GT	1305.00	435
1326-3GT	1326.00	442
1335-3GT	1335.00	445
1374-3GT	1374.00	458
1386-3GT	1386.00	462
1422-3GT	1422.00	474
1446-3GT	1446.00	482
1521-3GT	1521.00	507
1524-3GT	1524.00	508
1545-3GT	1545.00	515
1569-3GT	1569.00	523
1596-3GT	1596.00	532
1650-3GT	1650.00	550
1680-3GT	1680.00	560
1695-3GT	1695.00	565
1722-3GT	1722.00	574
1851-3GT	1851.00	617
1860-3GT	1860.00	620
1947-3GT	1947.00	649
2025-3GT	2025.00	675
2100-3GT	2100.00	700
2229-3GT	2229.00	743
2340-3GT	2340.00	780
2490-3GT	2490.00	830
2547-3GT	2547.00	849
2790-3GT	2790.00	930