


5M

 
〈ピッチ:5.0mm〉

● ベルト歯形寸法

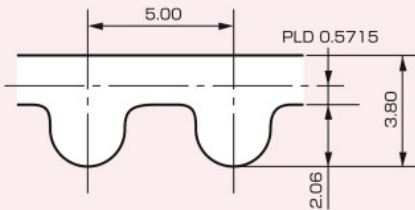

● ベルト呼称例

475-5M-15




● プーリ歯形寸法



● プーリ呼称例

P 20-5M-15-6F

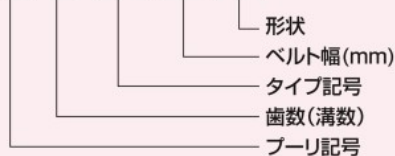

5Mプーリ

P.126

参照

ベルトサイズ一覧表

呼称	ピッチ周長(mm)	歯数
175-5M	175.00	35
225-5M	225.00	45
230-5M	230.00	46
245-5M	245.00	49
260-5M	260.00	52
295-5M	295.00	59
300-5M	300.00	60
320-5M	320.00	64
350-5M	350.00	70
375-5M	375.00	75
385-5M	385.00	77
400-5M	400.00	80
405-5M	405.00	81
410-5M	410.00	82
420-5M	420.00	84
450-5M	450.00	90
465-5M	465.00	93
475-5M	475.00	95
500-5M	500.00	100
520-5M	520.00	104
550-5M	550.00	110
560-5M	560.00	112
565-5M	565.00	113
575-5M	575.00	115
580-5M	580.00	116
600-5M	600.00	120
615-5M	615.00	123
625-5M	625.00	125
635-5M	635.00	127
640-5M	640.00	128
645-5M	645.00	129
670-5M	670.00	134
695-5M	695.00	139
710-5M	710.00	142
720-5M	720.00	144
740-5M	740.00	148
770-5M	770.00	154
775-5M	775.00	155
800-5M	800.00	160
810-5M	810.00	162

呼称	ピッチ周長(mm)	歯数
830-5M	830.00	166
845-5M	845.00	169
860-5M	860.00	172
870-5M	870.00	174
890-5M	890.00	178
900-5M	900.00	180
920-5M	920.00	184
930-5M	930.00	186
940-5M	940.00	188
950-5M	950.00	190
965-5M	965.00	193
975-5M	975.00	195
1000-5M	1000.00	200
1025-5M	1025.00	205
1040-5M	1040.00	208
1050-5M	1050.00	210
1125-5M	1125.00	225
1135-5M	1135.00	227
1145-5M	1145.00	229
1225-5M	1225.00	245
1235-5M	1235.00	247
1250-5M	1250.00	250
1270-5M	1270.00	254
1295-5M	1295.00	259
1350-5M	1350.00	270
1380-5M	1380.00	276
1420-5M	1420.00	284
1520-5M	1520.00	304
1595-5M	1595.00	319
1685-5M	1685.00	337
1690-5M	1690.00	338
1800-5M	1800.00	360
1870-5M	1870.00	374
2000-5M	2000.00	400
2350-5M	2350.00	470