




**No. B33 Short Bit (For Bit Holder)**

● Can be used by attaching to a bit holder.

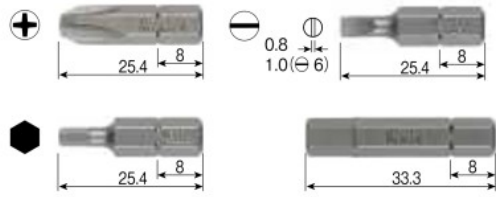


Model No. (mm)	Heat treatment classification	Tip	L	Inner Ctn. (mm)	Outer Ctn.	EDP No.
⊕1 × 25.4	H	⊕1	25.4	10	100	421231
⊕2 × 25.4	H	⊕2	25.4	10	100	421241
⊕3 × 25.4	G	⊕3	25.4	10	100	421242
⊖4 × 25.4	G	⊖4	25.4	10	100	421251
⊖6 × 25.4	G	⊖6	25.4	10	100	421252
H2 × 25.4	H	H2	25.4	10	100	421260
H2.5 × 25.4	H	H2.5	25.4	10	100	421261
H3 × 25.4	H	H3	25.4	10	100	421262
H4 × 33.3	H	H4	33.3	10	100	421263
H5 × 33.3	H	H5	33.3	10	100	421264
H6 × 33.3	H	H6	33.3	10	100	421265

Model No.	Contents	Set content	Inner Ctn.	Outer Ctn.	EDP No.
<b>B33 Driver Bit Set</b>	1 for each	⊕1, ⊕2, ⊕3, ⊖4, ⊖6 × 25.4 with holder	1	10	421270
<b>B33 Hex. Bit Set</b>	1 for each	H 2, 2.5, 3 × 25.4 H 4, 5, 6 × 33.3 with holder	1	10	421271

**No. B33 Short Bit (For Bit Holder)**

● Can be used by attaching to a bit holder.

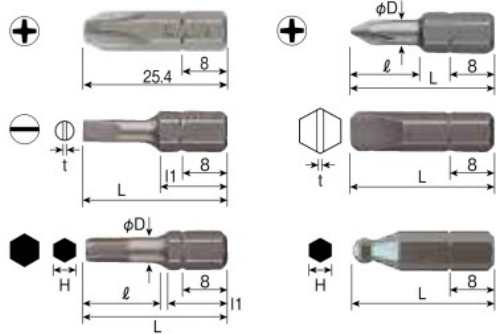

Model No. (mm)	Heat treatment classification	Tip	φD	ℓ	l1	L (mm)	Outer Ctn.	EDP No.
★ 1001	H	⊕1	—	—	—	25.4	10	487105
★ 3002R/25	H	⊕2	6	12	—	25	10	489003
★ 1002	H	⊕2	—	—	—	25.4	10	487106
★ 1002X	X	⊕2	—	—	—	25.4	10	487502
★ 5603/25	H	⊖3 × 0.5t	—	—	11	25	10	489061
★ 5635/25	H	⊖3.5 × 0.55t	—	—	11	25	10	489678
★ 1501	H	⊖4.76 × 0.86t	—	—	—	25.4	10	487120
★ 1502	H	⊖5.56 × 1.02t	—	—	—	25.4	10	487121
★ 1503	H	⊖6.35 × 1.07t	—	—	—	25.4	10	487122
★ 1504	H	⊖7.14 × 1.17t	—	—	—	25.4	10	487123
★ 1505	H	⊖8 × 1.27t	—	—	—	25.4	10	487124
★ 30325/25	H	H2.5	3	4.5	11	25	10	489052
★ 21005	H	H5	—	12.7	18	33.3	10	487143
★ 3034/25	H	H4	4.75	6	11	25	10	489054
★ 3036/25	H	H6	—	8	—	25	10	489056
★ 3038/25	H	H8	—	10	—	25	10	489057
★ 3760/25	H	BP H6	—	—	—	25	10	446407

**No. B33 3-Flute Bit (For Bit Holder)**

 
● Can be used by attaching to a bit holder.



Model No. (mm)	Heat treatment classification	Tip	L (mm)	Inner Ctn.	EDP No.
★ 4002	H	TW2	25.4	10	446412
★ 4004	H	TW4	25.4	10	446414

**No. B33 Square Bits (For Bit Holder)**

● Can be used by attaching to a bit holder.



Size Tip × Overall Length (mm)	Heat treatment classification	Inner Ctn.	EDP No.
<b>SQ1 × 25.4 (3001)</b>	H	10	487150



**No. B33 Hex Bit (For Bit Holder)**

● Can be used by attaching to a bit holder.



Model No. (mm)	Heat treatment classification	Tip	ℓ	L (mm)	Inner Ctn.	EDP No.
★ 3048/34	H	H8	16	34	10	489105
★ 3050/34	H	H10	16	34	10	489106