


TOPJOB® S

Ferrules for Rail-Mounted Terminal Blocks and Crimping Tools

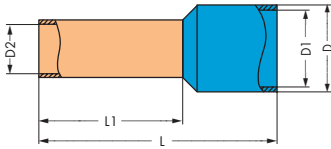








Ferrule, insulated, tin-plated, electrolytic copper, gastight crimped	Variocrimp 4 crimping tool for insulated and uninsulated ferrules 0.25 mm² ... 4 mm²/AWG 24 ... 12	Variocrimp 16 crimping tool for insulated and uninsulated ferrules 6 mm² ... 16 mm²/AWG 10 ... 6
---	--	--



Item No.	Pack. Unit	Item No.	Pack. Unit	Item No.	Pack. Unit
Ferrule, insulated, according to DIN 46228, part 4/09.90		Variocrimp 4 crimping tool, 0.25 mm² ... 4 mm²/AWG 24 ... 12		Variocrimp 16 crimping tool, 6 mm² ... 16 mm²/AWG 10 ... 6	
○ white	216-241	1000	206-204	1	206-216
○ gray	216-242	1000			
○ gray	216-262	1000			
● red	216-243	1000			
● red	216-263	1000			
● black	216-244	1000			
● black	216-264	1000			
● black	216-284	1000			
● blue	216-246	1000			
● blue	216-266	1000			
● blue	216-286	1000			
○ gray	216-267	1000			
○ gray	216-287	500			
● yellow	216-208	100			
● yellow	216-288	500			
● blue	216-289	500			
● blue	216-210	100			

Ferrules

Technical Data

Ferrule, insulated,	Ferrule, insulated,	Ferrule, insulated,
 sleeve for 0.5 mm²/AWG 22, 12 mm strip length, L: 16 mm, L1: 10 mm, D: 3.1 mm, D1: 2.6 mm, D2: 1 mm white 216-241	 sleeve for 1 mm²/AWG 18, 12 mm strip length, L: 16 mm, L1: 10 mm, D: 3.5 mm, D1: 3 mm, D2: 1.4 mm red 216-243	 sleeve for 1.5 mm²/AWG 16, 14 mm strip length, L: 18 mm, L1: 12 mm, D: 4 mm, D1: 3.5 mm, D2: 1.7 mm black 216-264
 sleeve for 0.75 mm²/AWG 20, 12 mm strip length, L: 16 mm, L1: 10 mm, D: 3.3 mm, D1: 2.8 mm, D2: 1.2 mm gray 216-242	 sleeve for 1 mm²/AWG 18, 14 mm strip length, L: 18 mm, L1: 12 mm, D: 3.5 mm, D1: 3 mm, D2: 1.4 mm red 216-263	 sleeve for 1.5 mm²/AWG 16, 20 mm strip length, L: 24 mm, L1: 18 mm, D: 4 mm, D1: 3.5 mm, D2: 1.7 mm black 216-284
 sleeve for 0.75 mm²/AWG 20, 14 mm strip length, L: 18 mm, L1: 12 mm, D: 3.3 mm, D1: 2.8 mm, D2: 1.2 mm gray 216-262	 sleeve for 1.5 mm²/AWG 16, 12 mm strip length, L: 16 mm, L1: 10 mm, D: 4 mm, D1: 3.5 mm, D2: 1.7 mm black 216-244	 sleeve for 2.5 mm²/AWG 14, 12 mm strip length, L: 17 mm, L1: 10 mm, D: 4.7 mm, D1: 4.2 mm, D2: 2.2 mm blue 216-246