
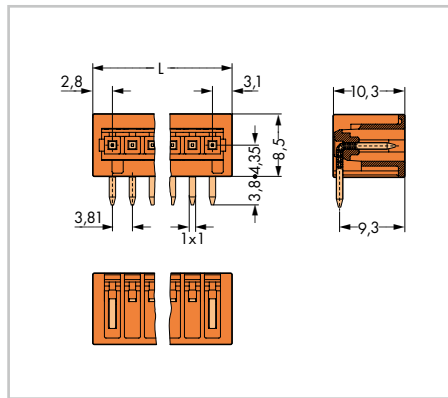


# Male Headers with Solder Pins MCS MINI

<b>With straight solder pins</b> <b>Pin spacing: 3.81 mm / 0.15 in.</b>		<b>With angled solder pins</b> <b>Pin spacing: 3.81 mm / 0.15 in.</b>	
160 V/2.5 kV/2 10 A	300 V/10 A	160 V/2.5 kV/2 10 A	300 V/10 A

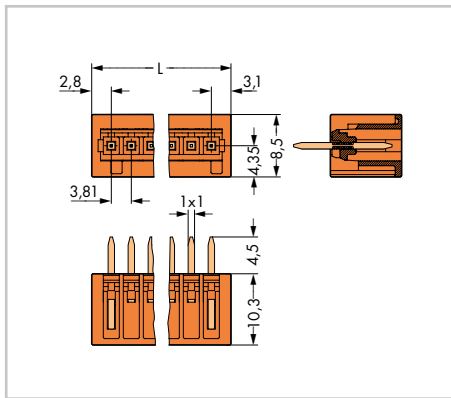

$L = (\text{pole no.} - 1) \times \text{pin spacing} + 5.9 \text{ mm}$

Pole No.	Item No.	Pack. Unit	Pole No.	Item No.	Pack. Unit
<b>Male header with straight solder pins, orange</b>			<b>Male header with angled solder pins, orange</b>		
2	734-232	200	2	734-262	200
3	734-233	200	3	734-263	200
4	734-234	200	4	734-264	200
5	734-235	200	5	734-265	200
6	734-236	100	6	734-266	100
8	734-238	100	8	734-268	100
9	734-239	100	9	734-269	100
10	734-240	100	10	734-270	100
12	734-242	100	12	734-272	100
14	734-244	100	14	734-274	100
16	734-246	50	16	734-276	50
18	734-248	50	18	734-278	50
19	734-249	50	19	734-279	50
20	734-250	50	20	734-280	50