



チーズ

T

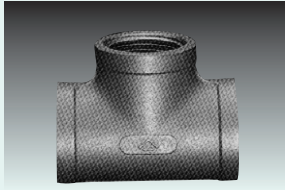


呼び (B)	L
1/8	19
1/4	21.5
3/8	23.5
1/2	28.5
3/4	33.5
1	38.5

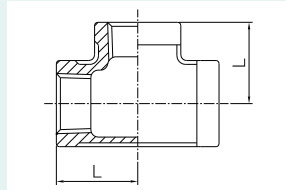


呼び (B)	L
1 1/4	45.5
1 1/2	50
2	58
2 1/2	70
3	78.5
4	97.5

クロス

CR

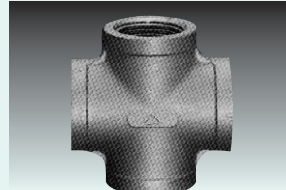


呼び (B)	L
1/8	17
1/4	19
3/8	23
1/2	27
3/4	32
1	38

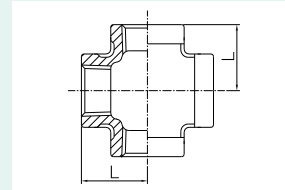


呼び (B)	L
1 1/4	46
1 1/2	48
2	58
2 1/2	69
3	78
4	97

径違いチーズ

RT

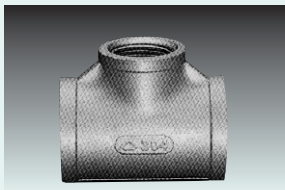


呼び (B)	L1	L2
1/4x1/8	18	19
3/8x1/8	19	21
3/8x1/4	20	22
1/2x1/8	22.5	23.5
1/2x1/4	24	24.5
1/2x3/8	26	25
3/4x1/4	25	27
3/4x3/8	28	28
3/4x1/2	30.5	32
1x1/4	28	31
1x3/8	30	31
1x1/2	32	33.5
1x3/4	34.5	31
1 1/4x3/8	32	36
1 1/4x1/2	34	37.5
1 1/4x3/4	39	40
1 1/4x1	40	42.5

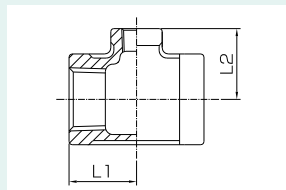


呼び (B)	L1	L2
1 1/2x3/8	34	40
1 1/2x1/2	35	42
1 1/2x3/4	38	42
1 1/2x1	41.5	45
1 1/2x1 1/4	45	48
2x1/2	38	48
2x3/4	41.5	49.5
2x1	44.5	51
2x1 1/4	48	54.5
2x1 1/2	52.5	55.5

径違いソケット

RS

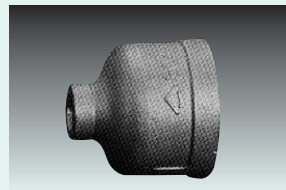


呼び (B)	L
1/4x1/8	26
3/8x1/8	28
3/8x1/4	29
1/2x1/8	34
1/2x1/4	34
1/2x3/8	34
3/4x1/8	38.5
3/4x1/4	38
3/4x3/8	38.5
3/4x1/2	37
1x1/8	42.5
1x1/4	42.5
1x3/8	42
1x1/2	42
1x3/4	42.5
1 1/4x1/2	48
1 1/4x3/4	48
1 1/4x1	52
1 1/2x3/8	47.5
1 1/2x1/2	52
1 1/2x3/4	52
1 1/2x1	52.5
1 1/2x1 1/4	53.5

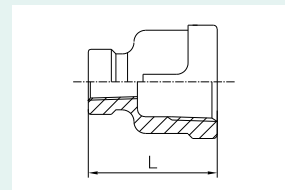


呼び (B)	L
2x1/2	51
2x3/4	51
2x1	56
2x1 1/4	56
2x1 1/2	57.5
2 1/2x1	60
2 1/2x1 1/4	60.5
2 1/2x1 1/2	60.5
2 1/2x2	61
3x1	62
3x1 1/4	62
3x1 1/2	61.5
3x2	62
3x2 1/2	60.5

ユニオン

U

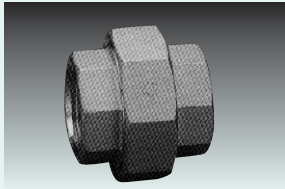

呼び (B)	L	SW1	SW2
1/8	29	14.5	25
1/4	38	18.5	30
3/8	38	22	37
1/2	41	27	42
3/4	50.5	32	49.5
1	48	41	59

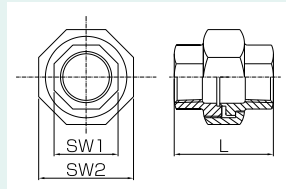


呼び (B)	L	SW1	SW2
1 1/4	59.5	49.5	71
1 1/2	65	56	77
2	68.5	67.5	92
2 1/2	80	83.5	112
3	89	96.5	126
4	108	123	157

ユニオンエルボ

UL



呼び (B)	L1	L2	SW1	SW2
3/8	50.5	25	22	37
1/2	54.5	28	27	42
3/4	62	33	32	49.5
1	69	38	41	59

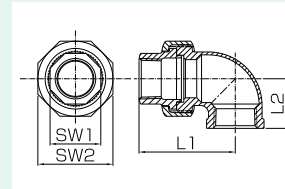

※ガスケットはテフロンパッキンを付属しております。

※ガスケットはテフロンパッキンを付属しております。

単位：mm