

109 Series



Angle type



Straight type

Necessary for hot water controlled radiator heater.

109 series return valve—Able to control the flow minutely.

■ Specifications


Application	Cold and hot water	
Maximum pressure	1.0 MPa	
Maximum temperature	120°C	
Material	Body	Brass (nickel plate)
	Valve	Brass
Connection	Inlet: JIS Rp screwed Outlet: JIS R (union joint)	

■ Model and Dimensions (mm)

Angle	Nominal size	d	L	L ₁	L ₂	Model No.
	15A	1/2	58	26	52	No.109-0662
	20A	3/4	66	29	58	No.109-0663

Straight	Nominal size	d	L	L ₁	L ₂	Model No.
	15A	1/2	80	53.5	34.0	No.109-0762
	20A	3/4	91	62.0	34.5	No.109-0763

· Angle type

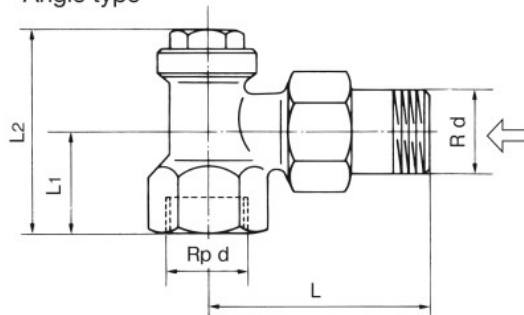

· Straight type

