

Bearings with Housings

Bottom Mount


Fasten it from the bottom of the holder. Suitable when space needs to be secured.




Type		Material		Surface Treatment		Accessory	
h Selectable	h Configurable	Bearing	Housing	Housing	Retaining Ring		
BGBK	BGBFB	Steel	S45C Equivalent	Black Oxide	Spring Steel		
BGBK	BGBF			Electroless Nickel Plating			
BGBK	BGBFA	2000 Aluminum Alloy	2000 Aluminum Alloy	Clear Anodize	SUS304 Equivalent		
BGBKSA	BGBFSA						
BGBKS	BGBFS	Stainless Steel	SUS304 Equivalent	-			

Bearing Accuracy: JIS B 1514 Class 0

* Bearings with Rubber Seals (VV and DD) are all made of steel.

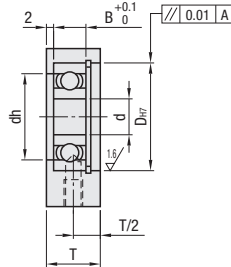

6.3 / (1.6)

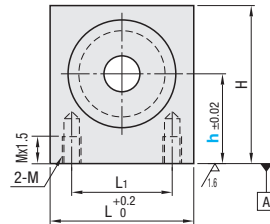

Type	Bearing No.	Seal	h		d	Dh7	dh	B	H	L	L1	T	M (Coarse)	Unit Price															
			Selectable	Configurable 1mm Increment										h Selectable					h Configurable										
														BGBK	BGBK	BGBKSA	BGBKSA	BGBKS	BGBFB	BGBF	BGBFA	BGBFSA	BGBFS						
h Selectable BGBK BGBK BGBKSA BGBKSA BGBKS	623	ZZ Double Shielded (x1.0)	15 20 25	15-30	3	10	+0.015	7	4	h+9	20	10	10	M4															
	624				4	13		9	5	h+11	22	14	10																
	605				5	14		10	5	h+11	24	16	10																
	625				5	16		12	5	h+12	28	16	10																
	606				6	17		13	6	h+13	34	22	12																
	626		6	19		15	6	h+14	36	24	12																		
	608		8	22		18	7	h+15	38	26	12																		
	628		8	24		20	8	h+16	34	22	15																		
	6900		10	22		19	6	h+15	32	20	12																		
	6000		10	26		22	8	h+17	38	26	15																		
6200	10	30		24	9	h+19	40	28	15																				
6901	12	24		21	6	h+16	36	24	12																				
6001	12	28		24	8	h+18	40	28	15																				
6201	12	32		26	10	h+20	42	30	16																				
6902	15	28		25	7	h+18	42	30	12																				
6002	15	32		28	9	h+20	50	36	15																				
6202	15	35		29	11	h+22	44	30	17																				
6903	17	30		27	7	h+19	42	30	13																				
6003	17	35		31	10	h+22	50	36	16																				
6203	17	40		34	12	h+24	48	36	20																				
6904	20	37		34	9	h+23	45	31	15																				
6004	20	42		36	12	h+25	54	38	19																				
6204	20	47		40	14	h+28	60	44	20																				
6005	25	47		41	12	h+28	62	46	19																				
6205	25	52		45	15	h+31	70	50	22																				
6006	30	55		48	13	h+32	74	54	20																				
6206	30	62		55	16	h+36	82	62	23																				

The price of sealed VV and DD are the price shown in the table multiplied by 1.1.

Check for available sizes in the price list. * No. 623, 624, 605 and 606 are not available for VV (Non-contact Sealed).



Ordering Example

Part Number				h
Type	Bearing	Seal		
BGBK	6000	VV	-	30
BGBFS	6204	ZZ	-	55



Alterations



Part Number - h - (KCC, NA, KCC)
BGBF6000ZZ - 35 - KCC

Alterations	Bearings, Retaining Rings Not Assembled	C2 Chamfer	C Chamfer								
Code	NA	KCC	KCC								
Spec.	Bearings and retaining rings are shipped unassembled to the housing.	C2 chamfer is done on the top edge surface.	C chamfer (45°) is done on both top edge corners. Ordering Code: KCC <table border="1"> <thead> <tr> <th>d</th> <th>KCC</th> </tr> </thead> <tbody> <tr> <td>3-8</td> <td>5</td> </tr> <tr> <td>10-20</td> <td>10</td> </tr> <tr> <td>25, 30</td> <td>12</td> </tr> </tbody> </table>	d	KCC	3-8	5	10-20	10	25, 30	12
d	KCC										
3-8	5										
10-20	10										
25, 30	12										

Applicable to h Configurable Type only.