


Guides

Straight, L-Shaped, Height Adjusting, Pedestal, Angle


Features: Each of sizes (in particular, H Dimensions) are downsized for the Compact Type, the newly added lineup. Useful in limited spaces.

■ Straight Type



RoHS10

Part Number		Material	Hardness	Surface Treatment
Compact	Standard			
WGHBC	WGHB	S45C Equivalent	40HRC~	Black Oxide
WGHMC	WGHM			Electroless Nickel Plating
-	WGHHB			Black Oxide
-	WGHHM			Electroless Nickel Plating
-	WGHA	Aluminum Alloy	-	-
WGHSC	WGHS	SUS304		
WGHJC	WGHJ	Polyacetal		
WGHNC	WGHN	MC Nylon		
-	WGHNE	Conductive MC Nylon R2	-	-
-	WGHPT	PTFE		

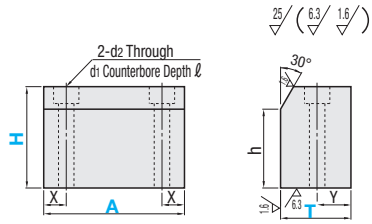


Part Number	A Selection	H 1mm Increment	T	h	X	Y	d1	d2	ℓ
(Compact) WGHBC WGHMC WGHJC WGHNC	17 20	6~10	10	H-3	4.5	4.5	6.5	3.5	3.5
	20 30		12		4.5	4.5	6.5	3.5	3.5
(Standard) WGHB WGHM WGHHB WGHNC WGHJ WGHN WGHNE WGHPT	20 30 40 50	10~30	12	H-5	5	5	6.5	3.5	3.5
	20 30 40 50		15		5	6	8	4.5	4.5
	30 40 50 60		20		7	9	9.5	5.5	5.5
	30 40 50 60	15~30	25		8	11	11	6.5	6.5
	40 50 60		30		11	14	14	9	9
	40 50 60		30		11	14	14	9	9

Part Number - A - H - T
WGHJ - 40 - 10 - 20


T	Unit Price														
	Compact					Standard									
	WGHBC	WGHMC	WGHSC	WGHJC	WGHNC	WGHB	WGHM	WGHHB	WGHHM	WGHA	WGHS	WGHJ	WGHN	WGHNE	WGHPT
10															
12															
15															
20															
25															
30															

■ L-Shaped Type



RoHS10

Part Number		Material	Hardness	Surface Treatment
Compact	Standard			
WGLBC	WGLB	S45C Equivalent	40HRC~	Black Oxide
WGLMC	WGLM			Electroless Nickel Plating
-	WGLHB			Black Oxide
-	WGLHM			Electroless Nickel Plating
-	WGLA	Aluminum Alloy	-	-
WGLSC	WGLS	SUS304		
WGLJC	WGLJ	Polyacetal		
WGLNC	WGLN	MC Nylon		
-	WGLNE	Conductive MC Nylon R2	-	-
-	WGLPT	PTFE		

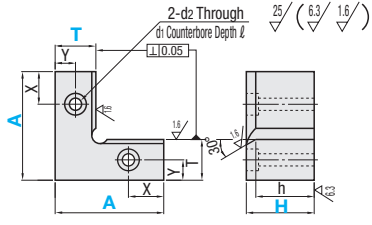

Part Number	A Selection	H 1mm Increment	T	h	X	Y	d1	d2	ℓ
(Compact) WGLBC WGLMC WGLJC WGLNC	17 20	6~10	10	H-3	4.5	4.5	6.5	3.5	3.5
	20 30		12		4.5	4.5	6.5	3.5	3.5
(Standard) WGLB WGLM WGLHB WGLNC WGLJ WGLN WGLNE WGLPT	20 30 40 50	10~30	12	H-5	5	5	6.5	3.5	3.5
	20 30 40 50		15		5	6	8	4.5	4.5
	30 40 50 60		20		7	9	9.5	5.5	5.5
	30 40 50 60	15~30	25		8	11	11	6.5	6.5
	40 50 60		30		11	14	14	9	9
	40 50 60		30		11	14	14	9	9

Part Number - A - H - T
WGLMC - 15 - 8 - 10

T	Unit Price														
	Compact					Standard									
	WGLBC	WGLMC	WGLSC	WGLJC	WGLNC	WGLB	WGLM	WGLHB	WGLHM	WGLA	WGLS	WGLJ	WGLN	WGLNE	WGLPT
10															
12															
15															
20															
25															
30															