


Plastic Circular Posts

One End Tapped / Both Ends Tapped

For products uncovered by the e-Catalog Standard, see P.131.


Threaded inserts are added to the main body (resin) to strengthen the tapped holes.

Plastic Circular Post




Type				Material	Color	Threaded Insert Material
One End Tapped	Both Ends Tapped	One End Threaded	Both Ends Threaded			
PHRF	PLRF	PHNRF	PLNRF	Polyacetal	White	SUS304

• One End Tapped, One End Threaded Insert

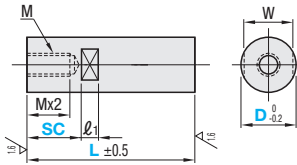

• Both Ends Tapped, Both Ends Threaded Insert

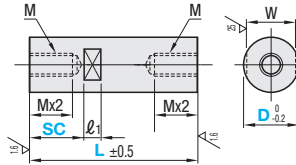

RoHS10 SCs-L1 Characteristic Values P.981

Part Number		L	SC	M	W	l1
Type	D	1mm Increment	1mm Increment	(Coarse)		
	6	20~50	0~42	M 3	5	8
	8	25~150	0~142	M 4	7	
	10	30~350	0~342	M 5	8	
One End Tapped Both Ends Tapped One End Threaded Both Ends Threaded	12	40~400	0~390	M 6	10	10
	15	50~500	0~490	M 8	13	
	20	60~500	0~490	M10	17	
	25	80~600	0~590	M12	22	
	30	100~700	0~685	M16	27	

Ordering Example

Part Number - L - SC

PHRF10 - 300 - SC200

PLNRF20 - 400 - SC310

One End Tapped

Part Number	Unit Price					
	Type	D	Min. L ~ 200	L201~400	L401~600	L601~700
PHRF	6		-	-	-	-
	8		-	-	-	-
	10		-	-	-	-
	12		-	-	-	-
	15		-	-	-	-
	20		-	-	-	-
	25		-	-	-	-
	30		-	-	-	-

Both Ends Tapped

Part Number	Unit Price					
	Type	D	Min. L ~ 200	L201~400	L401~600	L601~700
PLRF	6		-	-	-	-
	8		-	-	-	-
	10		-	-	-	-
	12		-	-	-	-
	15		-	-	-	-
	20		-	-	-	-
	25		-	-	-	-
	30		-	-	-	-

One End Threaded

Part Number	Unit Price					
	Type	D	Min. L ~ 200	L201~400	L401~600	L601~700
PHNRF	6		-	-	-	-
	8		-	-	-	-
	10		-	-	-	-
	12		-	-	-	-
	15		-	-	-	-
	20		-	-	-	-
	25		-	-	-	-
	30		-	-	-	-

Both Ends Threaded

Part Number	Unit Price					
	Type	D	Min. L ~ 200	L201~400	L401~600	L601~700
PLNRF	6		-	-	-	-
	8		-	-	-	-
	10		-	-	-	-
	12		-	-	-	-
	15		-	-	-	-
	20		-	-	-	-
	25		-	-	-	-
	30		-	-	-	-