


Hex Screws



Type	M Material	H Hardness	S Surface Treatment	Strength Class
RCB	SCM435	32~39HRC	Black Oxide	10.9
RSCB	SUS304 Equivalent	-	-	A2-50

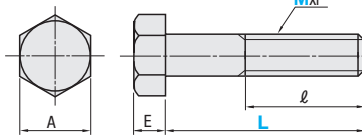

MxP	A	E
4x0.7	7.0	2.8
5x0.8	8.0	3.5
6x1.0	10	4.0
8x1.25	13	5.5
10x1.5	17	7.0
12x1.75	19	8.0
16x2.0	24	10

RCB (Black Oxide)

Part Number		Unit Price	Volume Discount Rate			
Type	M-L		1 ~ 99 pc(s)	100 ~ 159 pcs.	160 ~ 199 pcs.	200 ~ 500 pcs.
RCB	5-8					
	10					
	12					
	15					
	20					
	25					
	30					
	35					
	40					
	6-10					
	12					
	15					
	20					
	25					
	30					
	35					
	40					
	45					
	50					
	55					
	60					
	65					
	70					
	75					
	8-10					
	12					
	15					
	20					
	25					
	30					
	35					
	40					
	45					
	50					
	55					
	60					
	65					
	70					
	75					
	8-10					
12						
15						
20						
25						
30						
35						
40						
45						
50						
55						
60						
65						
70						
75						
80						
90						
100						
10-15						
20						
25						
30						

Part Number		Unit Price	Volume Discount Rate			
Type	M-L		1 ~ 99 pc(s)	100 ~ 159 pcs.	160 ~ 199 pcs.	200 ~ 500 pcs.
RCB	10-35					
	40					
	45					
	50					
	55					
	60					
	65					
	70					
	75					
	80					
	90					
	100					
	12-20					
	25					
	30					
	35					
	40					
	45					
	50					
	55					
	60					
	65					
	70					
	75					
	80					
	90					
	100					
	12-20					
	25					
	30					
	35					
	40					
	45					
	50					
	55					
	60					
	65					
	70					
	75					
	80					
90						
100						
12-20						
25						
30						
35						
40						
45						
50						
55						
60						
65						
70						
75						
80						
90						
100						
10-15						
110						
120						
130						
16-30						
35						
40						
45						
50						
55						
60						
65						
70						
75						
80						
80						
80						
80						
90						
90						
100						
110						
120						
130						

RSCB (Stainless Steel)

Part Number		Unit Price	Volume Discount Rate			
Type	M-L		1 ~ 49 pc(s)	50 ~ 99 pcs.	100 ~ 199 pcs.	200 ~ 500 pcs.
RSCB	4-8					
	10					
	12					
	15					
	20					
	25					
	30					
	35					
	40					
	5-8					
	10					
	12					
	15					
	20					
	25					
	30					
	35					
	40					
	45					
	50					
	6-10					
	12					
	15					
	20					
	25					
	30					
	35					
	40					
	45					
	50					
	55					
	60					
	65					
	70					
	75					
	8-10					
	12					
	15					
	20					
	25					
30						
35						
40						
45						
50						
55						
60						
65						
70						
75						
80						
90						
100						

Part Number		Unit Price	Volume Discount Rate			
Type	M-L		1 ~ 49 pc(s)	50 ~ 99 pcs.	100 ~ 199 pcs.	200 ~ 500 pcs.
RSCB	8-60					
	65					
	70					
	75					
	80					
	90					
	100					
	10-15					
	20					
	25					
	30					
	35					
	40					
	45					
	50					
	55					
	60					
	65					
	70					
	75					
	80					
	90					
	100					
	12-20					
	25					
	30					
	35					
	40					
	45					
	50					
	55					
	60					
	65					
	70					
	75					
	80					
	90					
	100					

*The strength class signifies the screw's tensile strength.

(Ex.) 10.9
 This indicates that the minimum value for yielding point or proof stress is 90% of tensile strength.
 This indicates that the minimum value of tensile strength is 1040N/mm².

Ordering Example **Part Number**
RSCB12-100