


Hex Socket Extra Low Head Cap Screws / Hex Socket Head Cap Screws with Hole

Hex Socket Extra Low Head Cap Screws

RSCBT



RoHS10

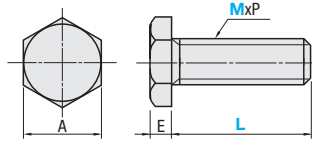

M Material: SUS304 Equivalent
*Strength Class: A2-50 Equivalent

Part Number		L							MxP	A	E	Unit Price	Volume Discount Rate
Type	M	4	5	6	8	10	12	15	20	25	30	1 ~ 49 pc(s).	50 ~ 300 pcs.
RSCBT	4	8	10	12	15	20	25	30	4x0.7	7	1.5		
	5	8	10	12	15	20	25	30	5x0.8	8			
	6	10	12	15	20	25	30	6x1.0	10	2.0			
	8	15	20	25	30	8x1.25	13						



Ordering Example


Part Number
RSCBT5-15

Hex Socket Head Cap Screws with Hole



RoHS10

Type	M Material	S Surface Treatment	H Hardness	Strength Class
RCBH	S33C	Black Oxide	22~32HRC	8.8 Equivalent
RSCBH	SUS304 Equivalent	-	-	A2-50 Equivalent

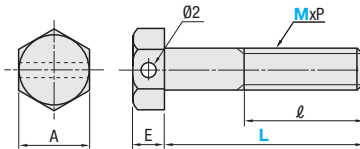

Type	M	Part Number							ℓ		MxP	A	E	Unit Price	
		L							RCBH	RSCBH				RCBH	RSCBH
RCBH RSCBH	6	10	12						Studs - Fully Threaded	Studs - Fully Threaded	6x1.0	10	4		
		15	20												
		25	30					18							
	8	15	20	25					Studs - Fully Threaded	Studs - Fully Threaded	8x1.25	13	5.5		
		30	35					22							
		40	45	50											
	10	20	25	30					Studs - Fully Threaded	Studs - Fully Threaded	10x1.5	17	7		
		35						26							
		40	45	50					28						
	12	30							Studs - Fully Threaded	Studs - Fully Threaded	12x1.75	19	8		
		35						30							
		40													
45							30								




Ordering Example

Part Number
RCBH6-10
RSCBH12-40



Example

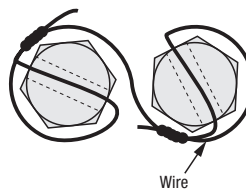

* The strength class signifies the screw's tensile strength.

(Ex.) A2-50

This indicates that the minimum value of tensile strength is 500N/mm².

The steel class is A2 (Austenitic Stainless Steel)