

Note that, for some of the types shown here, order might be unable to be received by the MISUMI Malaysia, Indonesia and/or India offices.

Nuts

⚠ These nuts are designed with smaller hex envelope and thickness than JIS standard to be used in limited spaces.


Compact Nuts



⚠ PACK - contains 10 pcs.



SNTRC
SNTRCS (Thin)
PACK-SNTRC
PACK-SNTRCS (Thin)

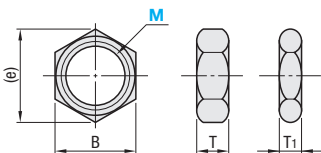

Material: SUS304
 * Strength Class SNTRC: 5T Equivalent
 SNTRCS: 4T Equivalent

Part Number	M	Coarse Pitch	B	(e)	T	T ₁	SNTRC		SNTRCS			
							Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate		
							1 - 4 pc(s)	5 - 99 pc(s)	100 - 500 pcs	1 - 4 pc(s)	5 - 99 pc(s)	100 - 500 pcs
4	0.7	6	6.9	2.4	2							
5	0.8	7	8.1	3.2	2.5							
6	1	8	9.2	3.6	3							
8	1.25	10	11.5	5	4							
10	1.5	13	15	6	4.5							
12	1.75	17	19.6	7	5.5							

⚠ For orders larger than indicated quantity, please check with WOS.

Part Number	M	Coarse Pitch	B	(e)	T	T ₁	Qty.	PACK-SNTRC		PACK-SNTRCS	
								Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
								1 - 2 pkg(s)	3 - 30 pkg(s)	1 - 2 pkg(s)	3 - 30 pkg(s)
4	0.7	6	6.9	2.4	2	10					
5	0.8	7	8.1	3.2	2.5	10					
6	1	8	9.2	3.6	3	10					
8	1.25	10	11.5	5	4	10					
10	1.5	13	15	6	4.5	10					
12	1.75	17	19.6	7	5.5	10					

⚠ For orders larger than indicated quantity, please check with WOS.




Part Number
SNTRCS
PACK-SNTRC4

Tall Nuts



Type	Material	Surface Treatment	Hardness
NT	S45C	Trivalent Bright Chromate Plating	25~30HRC
SNT	SUS304	-	-

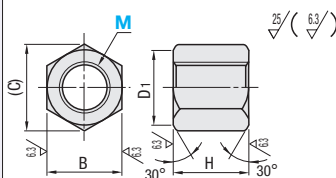


Part Number	M	Coarse Pitch	H	B	(C)	D ₁	NT		SNT	
							Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
							1 - 49 pc(s)	50 - 500 pcs	1 - 49 pc(s)	50 - 500 pcs
6	9	10	11.5	9.8						
8	12	13	15	12.5						
10	15	17	19.6	16.5						
12	18	19	21.9	18						
16	24	24	27.7	23						
20	30	30	34.6	29						
24	36	36	41.6	34						

⚠ For orders larger than indicated quantity, please check with WOS.




Part Number
NT6

 Configurable Length Nuts



Type	Material	Surface Treatment
NTFL	SS400	Electroless Nickel Plating
NTFLS	SUS304	-

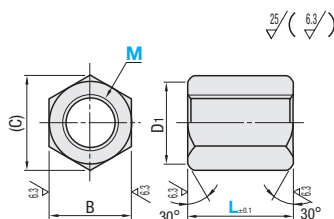

L Dimension Selectable

Part Number	M	L	B	(C)	D ₁	NTFL		NTFLS	
						Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
						1 - 19 pc(s)	20 - 49 pcs	50 - 99 pcs	100 - 200 pcs
						1 - 19 pc(s)	20 - 49 pcs	50 - 99 pcs	100 - 200 pcs
3	4	5	6	6.9	5.3				
		6 8 10							
4	5	6 8	7	8.1	6.8				
		10 12 15							
5	6	8 10 12	8	9.2	7.8				
		15 20							
6	10	12	10	11.5	9.8				
		15 20 25							
8	10	15	13	15	12.5				
		20 25 30							
10	10	20 25 30	17	19.6	16.5				
		40							



Part Number - L
NTFL6 - 10

L Dimension Configurable

Part Number	M	L	B	(C)	D ₁	Unit Price	
						NTFL	NTFLS
		1mm Increment					
3	3~10		6	6.9	5.3		
4	4~15		7	8.1	6.8		
5	5~20		8	9.2	7.8		
6	6~25		10	11.5	9.8		
8	8~30		13	15	12.5		
10	10~40		17	19.6	16.5		
12	10~50		19	21.9	18		
16	10~50		24	27.7	23		