


Note that, for some of the types shown here, order might be unable to be received by the MISUMI Malaysia, Indonesia, and/or India offices.


# Arrow Sign Stickers / Arrow Sign Plates / Open-Closed Sign Plates

## Straight / R Type

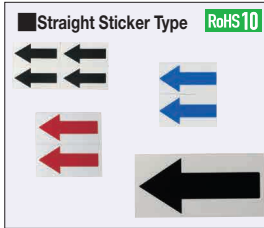

RoHS10


ARWS (Black)  
ARWSR (Red)  
ARWSB (Blue)

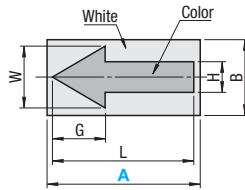

Part Number Type	A	Number of Panels per Label	Number of Labels per Package
ARWS ARWSR ARWSB	15	4	10 pcs.
	20	2	
	40	1	


Material: PET Film Operating Ambient Temperature: -20 ~ 80°C

Part Number Type	A	B	L	W	H	G	Unit Price 1 ~ 9 pkg(s).	Volume Discount Rate 10 ~ 50 pkgs.
ARWS ARWSR ARWSB	15	7.5	13	6	3	5		
	20	10	18	8.5	4	6.5		
	40	20	37	17	8	13		

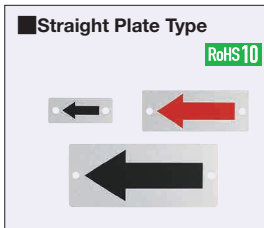

RoHS10

APWS (Black)  
APWSR (Red)

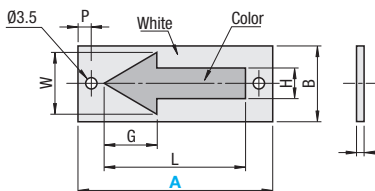


Order Unit: Pack 5 pcs. per package

Peel off the surface protection film before use.

Material: A1050P


Part Number Type	A	B	L	W	H	G	P	Unit Price 1 ~ 2 pkg(s).	Volume Discount Rate 3 ~ 4 pkgs.
APWS APWSR	30	12	17	8	4	6	3.5		
	50	20	36	16	8	12			
	70	30	55	24	12	19			

For orders larger than indicated quantity, please check with WOS.


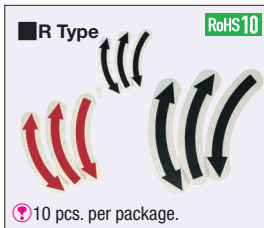


RoHS10

AWRB (Black)  
AWRBR (Red)

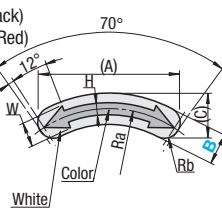

AWRL (Black)  
AWRLR (Red)  
AWRR (Black)  
AWRRR (Red)

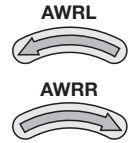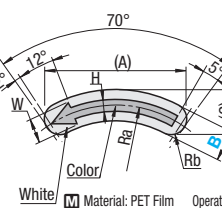

Material: PET Film Operating Ambient Temperature: -20 ~ 80°C

Part Number Type	B	Ra	W	H	Rb	(A)	(C)	Unit Price 1 ~ 9 pkg(s).	Volume Discount Rate 10 ~ 50 pkgs.
AWRB AWRBR	13	50	10	5	6.5	59.2	18.7		
AWRL AWRLR	20	75	15	8	10	88.9	28.4		
AWRR AWRRR	25	100	20	10	12.5	118.3	36.6		

For orders larger than indicated quantity, please check with WOS.

### Instruction of Use

- Choose a flat surface.
- Wipe the dirt off the surface.
- When putting a sticker on an exact position, moisten a large surface with a cloth beforehand.
- Separate a release paper and put the sticker, then press firmly.

### Material Characteristics (Features of PET Film)

Heat Resistance: 100°C x 7 Days ————— No change  
Oil Resistance: 72 hours in gear oil ————— No change  
Weather Resistance: 400 hours in weather meter — No change

Durability may vary under irregular conditions.

### Material Structure




### Open-Closed Sign Plates



Chains are removable.  
1 "Open" and 1 "Close" plates make a set.

RoHS10

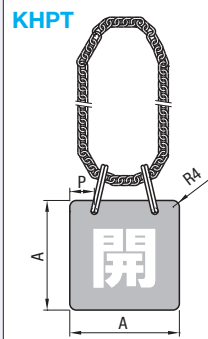

Material: Polyethylene Synthetic Paper Chain: SUS304

Part Number Type	No.	A	P	Ring Wire Dia.	Ring I.D.	Chain Length	Unit Price 1 ~ 2 pc(s).	Volume Discount Rate 3 ~ 20 pcs.
KHPT	70	67	15	1.4	22	600		

For orders larger than indicated quantity, please check with WOS.



Ordering Example

Part Number

AWRB-20  
KHPT-70