


■ **Features:** Bulk Packages of Screws with Captured Spring Washer HCBST. Bulk packages are cost effective for in-house stocks and large quantity use.

■ Screws with Captured Spring Washer Bulk Packages (500 pcs. per Package) **RoHS 10**



Screw	M Material: Structural Alloy Steel H Hardness: 32 ~ 44HRC *Strength Class 10.9 JIS 0209(Fg)
Washer	Spring Washer JIS B1251 Flat Washer JIS B1256
Surface Treatment	Trivalent Chromate

HCBST□-□□-SET1

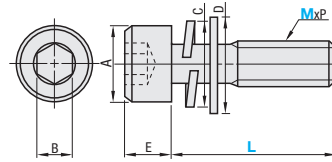

Part Number		MxP	A	E	B	C	D	Height of Spring Washer and Flat Washer when Tightened (Ref.)	Package Price	Price per 1 pc.	
Type	M -L-SET1 (500 pcs. per pkg.)										
HCBST	5 - 12 16	SET1	5x0.8	8.5	5	4	8.5	10	2.3		
	6 - 15 20 25		6x1.0	10	6	5	11.5	12.5	3.1		
	8 - 20 24 29		8x1.25	13	8	6	14.5	17	3.6		



Ordering Example
Part Number
HCBST6-15-SET1

■ List of Hex Socket Head Cap Screws with Captured Washer for each Bracket

Extrusion	Bracket	Hex Socket Head Cap Screws with Captured Washer	Bracket (With Tapped Hole)	Hex Socket Head Cap Screws with Captured Washer
HFS5 Series	HBLFSL5	Not applicable	HBLFSL5-C	Not applicable
	HBLFSN5	HCBST5-12	HBLFSN5-C	HCBST5-12
	HBLFSSW5	Not applicable	HBLFSSW5-C	Not applicable
	HBLFSD5	HCBST5-12	HBLFSD5-C	HCBST5-12
	HBLFUD5	HCBST5-16	HBLFUD5-C	HCBST5-16
	HBLT□5	HCBST5-12	HBLT□5-C	HCBST5-12
	HBLU□5	HCBST5-16	HBLU□5-C	HCBST5-16
HBS□5	Not applicable	-	-	
HBLFSNT5 (With Cover)	Not applicable	HBLFSNT5-C (With Cover)	Not applicable	
HFS6 Series	HBLFSL6	Not applicable	HBLFSL6-C	Not applicable
	HBLFSN6	Not applicable	HBLFSN6-C	Not applicable
	HBLFS6	HCBST6-15	HBLFS6-C	HCBST6-15
	HBLFSSW6(-50)	HCBST6-15	HBLFSSW6(-50)-C	HCBST6-15
	HBLFSD6	Not applicable	HBLFSD6-C	Not applicable
	HBLFSD6	Not applicable	HBLFSD6-C	Not applicable
	HBLSDW6(-50)	HCBST6-15	HBLSDW6(-50)-C	HCBST6-15
	HBLFTD6(-50)	HCBST6-20	HBLFTD6(-50)-C	HCBST6-20
	HBLFUD6(-50)	HCBST6-25	HBLFUD6(-50)-C	HCBST6-25
	HBLT□6(-50)	HCBST6-20	HBLT□6(-50)-C	HCBST6-20
HBLU□6(-50)	HCBST6-25	HBLU□6(-50)-C	HCBST6-25	
HBS□6(-50)	Not applicable	-	-	
HBLD□6 (Triangle)	Not applicable	-	-	
HBLFSNT6 (With Cover)	Not applicable	HBLFSNT6-C (With Cover)	Not applicable	
HFS8 Series	HBLFSN8(-45)	HCBST8-24	HBLFSN8(-45)-C	HCBST8-24
	HBLFS8	HCBST8-24	HBLFS8-C	HCBST8-24
	HBLFSSW8(-45)	HCBST8-24	HBLFSSW8(-45)-C	HCBST8-24
	HBLFSD8	HCBST8-24	HBLFSD8-C	HCBST8-24
	HBLFTD8	HCBST8-24	HBLFTD8-C	HCBST8-24
	HBLFUD8	HCBST8-29	HBLFUD8-C	HCBST8-29
	HBLT□8(-45)	HCBST8-24	HBLT□8(-45)-C	HCBST8-24
	HBLU□8(-45)	HCBST8-29	HBLU□8(-45)-C	HCBST8-29
	HBS□8(-45)	HCBST8-20	-	-
	HBLDSWT8(-45) (Triangle)	Not applicable	-	-
HBLFSNT8 (With Cover)	Not applicable	HBLFSNT8-C (With Cover)	Not applicable	

⚠ If not applicable, failures may occur such as screw heads interfering with each other.