

Screws for Aluminum Extrusions - Single Item / Bulk Packages


■ **Features:** Flathead screws for countersunk holes such as on hinges, etc.

Hex Socket Flat Head Cap Screws



Type	Material	Surface Treatment
HFBCM	SCM435	Trivalent Chromate
SHFBS	SUS304 Equivalent	-
HFBMB	SCM435	Trivalent Chromate (Black)

HFBCM (Trivalent Chromate)
SHFBS (Stainless Steel)
HFBMB (Trivalent Chromate, Black)

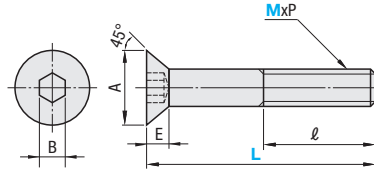

ℓ	Part Number Type M - L	MxP	A	E	B	HFBCM		SHFBS		HFBMB					
						Unit Price 1 ~ 39 pc(s)	Volume Discount Rate 40-99 100-120	Unit Price 1 ~ 39 pc(s)	Volume Discount Rate 40-99 100-120	Unit Price 1 ~ 39 pc(s)	Volume Discount Rate 40-99 100-120				
Full Thread	HFBCM 3 - 6	3x0.5	6	1.7	2	-	-	-	-	-	-				
	SHFBS 3 - 6					-	-	-	-	-					
	HFBMB 3 - 6					-	-	-	-	-					
Full Thread	HFBCM 4 - 6	4x0.7	8	2.3	2.5	-	-	-	-	-	-				
	SHFBS 4 - 6					-	-	-	-	-					
	HFBMB 4 - 6					-	-	-	-	-					
Full Thread	HFBCM 5 - 6	5x0.8	10	2.8	3	-	-	-	-	-	-				
	SHFBS 5 - 6					-	-	-	-	-					
	HFBMB 5 - 6					-	-	-	-	-					
16	HFBCM 6 - 8	6x1.0	12	3.3	4	-	-	-	-	-	-				
	SHFBS 6 - 8					-	-	-	-	-					
	HFBMB 6 - 8					-	-	-	-	-					
	HFBCM 8 - 12					8x1.25	16	4.4	5	-	-	-	-	-	-
	SHFBS 8 - 12									-	-	-	-	-	
Full Thread	HFBCM 10 - 16	10x1.5	20	5.5	6	-	-	-	-	-	-				
	SHFBS 10 - 16					-	-	-	-	-					
Full Thread	SHFBS 12 - 20	12x1.75	24	6.5	8	-	-	-	-	-	-				

Ordering Example


■ **Features:** Convenient screws for visible locations such as panel mounting.

Hex Socket Button Head Cap Screws



Type	Material	Hardness	Surface Treatment
HBCBM	SCM435	31HRC	Trivalent Chromate
SBCB	SUS304 Equivalent	-	-

HBCBM (Trivalent Chromate)
SBCB (Stainless Steel)

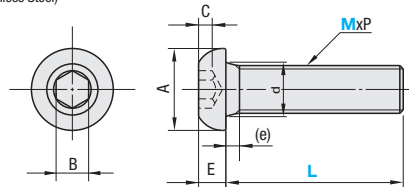

JIS B 1174

Part Number Type	M - L	A	E	B	C (Min.)	d	(e) (Max.)	Unit Price	Volume Discount Rate							
								1 ~ 199 pc(s)	200-299	300-499	500-600					
HBCBM	5 - 10	9.5	2.75	3	1.56	5.7	1.6	-	-	-	-					
	5 - 15							-	-	-	-					
	6 - 20	10.5	3.3	4	2.08	6.8	2	-	-	-	-					
	6 - 25							-	-	-	-					
	8 - 20							14	4.4	5	2.6	9.2	2.5	-	-	-
	8 - 25													-	-	-
8 - 35	-	-	-	-	-	-										
SBCB	4 - 12	7.5	2.2	2.5	1.3	4.7	2.1	-	-	-	-					
	6 - 25	10.5	3.3	4	2.08	6.8	3	-	-	-	-					
	8 - 25	14	4.4	5	2.6	9.2	3.5	-	-	-	-					
	8 - 35							-	-	-	-					
	10 - 30	17.5	5.5	6	3.12	11.2	4.5	-	-	-	-					
	12 - 35	21	6.6	8	4.16	14.2	5.25	-	-	-	-					

Ordering Example

For other specs., refer to P.185.