

Note that, for some of the types shown here, order might be unable to be received by the MISUMI Malaysia, and/or Indonesia offices.

Thin Magnetic Catches / Ultrathin Magnetic Catches / Adjustable Magnetic Catches

Thin Magnetic Catches

RoHS 10

MGCBU

| Part Name | Material | Surface Treatment |
|-------------|-----------|-------------------|
| Main Body | ABS Resin | - |
| Catch Plate | SPCC | Chrome Plating |
| Magnet | Ferrite | - |

10 pcs. per package. Order quantity should be noted.

| Part Number | P | A | t | F | B | P1 | Retention Force (kgf) | Mass (g) | Unit Price | Volume Discount Rate |
|--------------|----|------|-----|------|----|----|-----------------------|----------|----------------|----------------------|
| Type | L | | | | | | | | 1 ~ 9 pkg (s). | 10~100 |
| MGCBU | | | | | | | | | | |
| 49 | 34 | 17 | 6.5 | 16.5 | 24 | 13 | 0.9 | 15 | | |
| 59 | 44 | 23.5 | 6.7 | 23 | 34 | 20 | 2.0 | 33 | | |
| 70 | 55 | 24.5 | 7.7 | 24 | 45 | 30 | 3.5 | 49 | | |

Ordering Example
Part Number: **MGCBU49**

10 pcs. per package

Ultrathin Magnetic Catches

RoHS 10

MGCM

| Part Name | Material | Surface Treatment |
|-----------|-----------|-------------------|
| Main Body | SPCC | Nickel Plating |
| Magnet | Neodymium | Nickel Plating |


There is no catch plate.

| Part Number | No. | Retention Force (kgf) | Mass (g) | Unit Price | Volume Discount Rate |
|-------------|-----|-----------------------|----------|---------------|----------------------|
| Type | | | | 1 ~ 9 pc (s). | 10~100 |
| MGCM | | | | | |
| 1 | 1.5 | 12 | | | |
| 2 | 4 | 12 | | | |

Ordering Example
Part Number: **MGCM2**

ex Example

Use Flat Head Screw M3.

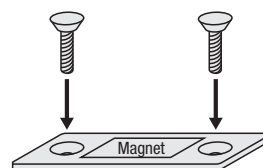

Adjustable Magnetic Catches

RoHS 10

AMGCB

| Part Name | Material | Surface Treatment |
|-------------|---------------|-------------------|
| Main Body | Polypropylene | - |
| Catch Plate | SPCC | Chrome Plating |
| Magnet | Ferrite | - |

| Part Number | Retention Force (kgf) | Mass (g) | Unit Price | Volume Discount Rate |
|--------------|-----------------------|----------|---------------|----------------------|
| Type | No. | | 1 ~ 9 pc (s). | 10~19 20~100 |
| AMGCB | | | | |
| 1 | 3.1 | 15 | | |

Features - The magnet position can be adjusted in 5mm increments.

Ordering Example
Part Number: **AMGCB1**

ex Example

The catch portion moves fore and aft when the adjusting screw is turned.

