

Air Blow Nozzles - Unit Type




Type			Material		
Point	Slit	Cross-Shaped	Main Body	Tube	Tip Nozzle Coupling
DYPN	DYPNB	DYPNC	Copper Pipe	Nylon	Brass (Chrome Plating)


Features

This product eliminates the need to purchase and assemble the couplings, copper pipes or tip nozzles. Tip Nozzles are selectable.



DYPN (Point)

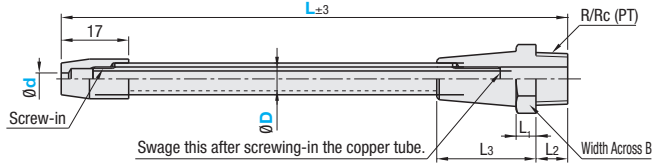

DYPNB (Slit)

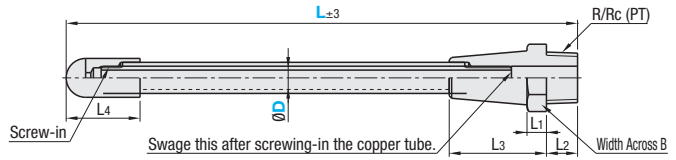

DYPNC (Cross-Shaped)

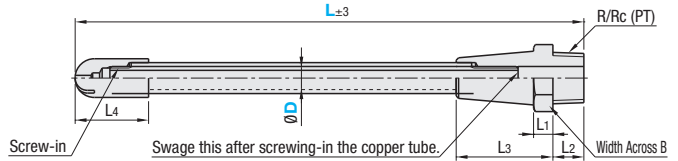 

Part Number		d	L 10mm Increment	Tube Color	L1	L2	L3	B	R/Rc (PT)	Unit Price	
Type	D									L150~250	L260~350
(Point) DYPN	4	1 1.5 2	150~350	A (Blue) B (Black) R (Red)	5	8	19	12	1/8		
	6	1.5 2 3					25	14	1/4		

Part Number		L 10mm Increment	Tube Color	w	L1	L2	L3	L4	B	R/Rc (PT)	Unit Price	
Type	D										L150~250	L260~350
(Slit) DYPNB	4	150~350	A (Blue) B (Black) R (Red)	0.5	5	8	19	18	12	1/8		
	6			1			25	19	1/4			
(Cross-Shaped) DYPNC	4	150~350	A (Blue) B (Black) R (Red)	0.5	5	8	19	18	14	1/8		
	6			1			25	19	1/4			

⊕ D dim. is the dimension of the copper pipe.

⊕ For orders larger than indicated quantity, please check with WOS.


Ordering Example

Part Number - d - L - Tube Color


DYPN4 - 1.5 - 150 - A

DYPNB4 - 150 - A


Air Flow Rate Property Table

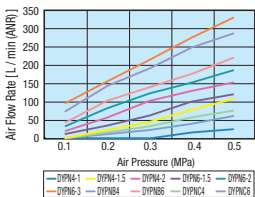

Quietness Property Table

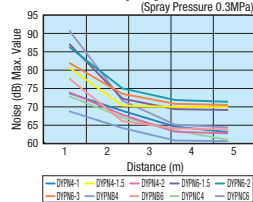

Air Colliding Force Property Table

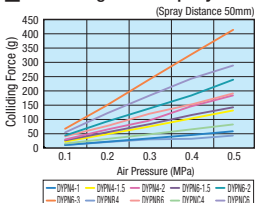

⊕ Values on the graph are for reference, not guaranteed.

